


Strangkühlkörper

Extruded Heatsinks

Dissipateurs extrudés

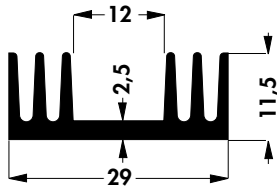


SK 09


20 37,5 50 1000 mm

TO 220 K


SK 09 37,5 TO 220

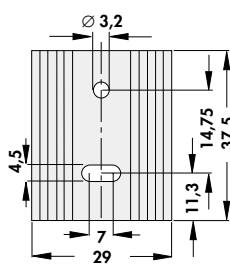


SK 09 37,5 TO 220/1  
SK 09 50,0 TO 220/1

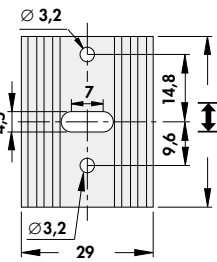



SK 09 50 TO 220

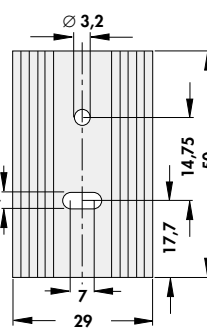

SK 09 20 TO 220

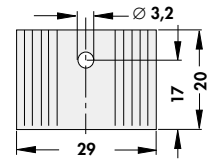

K/W

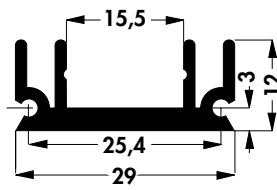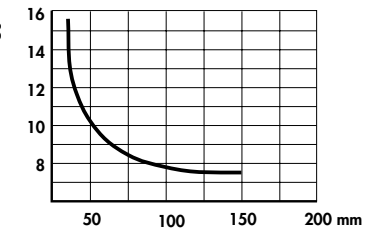


SK 145

20 37,5 50 1000 mm


TO 220

SK 145 mit Lötstiften → A 94


SK 145 20 TO 220

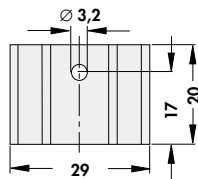


SK 145 37,5 TO 220

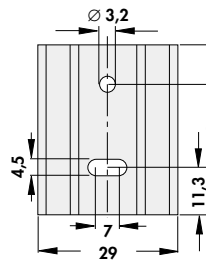

SK 145 50 TO 220

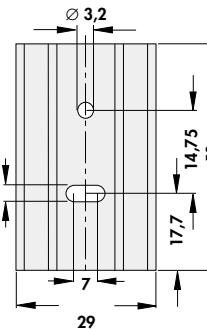

K/W

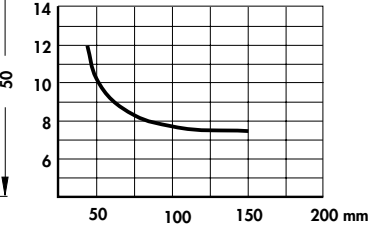


SK 145 avec broches à souder → A 94


SK 59

37,5 50 75 100 1000 mm

9/66 TO 220

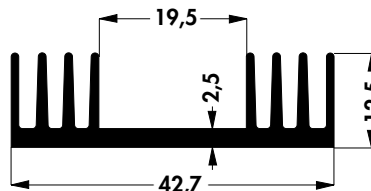


K/W

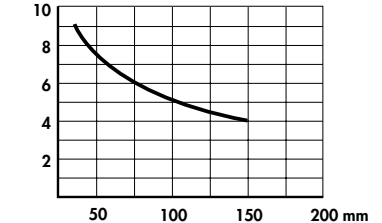


SK 122

37,5 50 100 mm

TO 3 9/66 CB

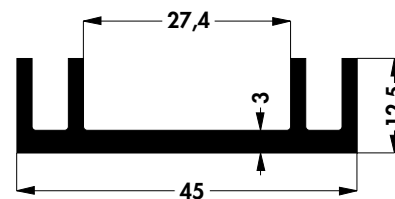


K/W

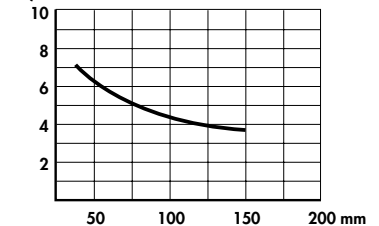

SK 78

37,5 50 75 100 1000 mm

TO 3 9/66 CB

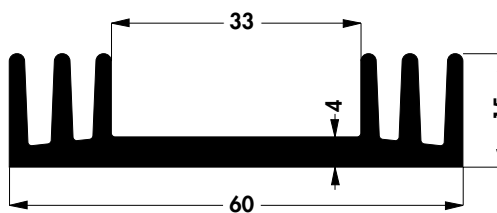

K/W

