


# IDC Cable mounting plugs – 2.54mm pitch 10-poles

Order code: 19-0066

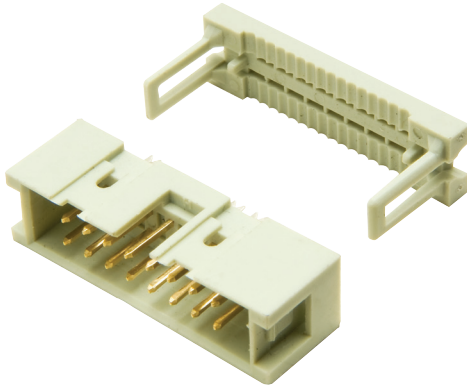

## Notes:

### 1. Material

- 1.1 Insulator: Thermoplastic (UL 94V-0)
- 1.2 Contact: Copper alloy

### 2. Specification

- 2.1 Storage temperature: -20°C to +70°C
- 2.2 Operating temperature: 0-85°C
- 2.3 Contact resistance: 20mΩ max.
- 2.4 Insulation resistance: 1000MΩ min.
- 2.5 Dielectric withstanding voltage:  
AC 500V per minute

