



40-way Single Row Right Angled PCB Header Plug – 2mm Pitch

Order code: 19-0078

Notes:


1. Material

- 1.1 Insulator: Thermoplastic (UL 94V-0)
- 1.2 Contact: Copper alloy


2. Specification

- 2.1 Current rating: 1.5 Amp
- 2.2 Insulation resistance: 1000MΩ min.
- 2.3 Dielectric withstanding: 600VAC
- 2.4 Contact resistance: 20mΩ max.
- 2.5 Operating temperature: -20°C to +80°C

No.	Description	Material	Plating
1	Housing	Thermoplastic	UL 94 V-0
2	Contact	Copper Alloy	Gold flash

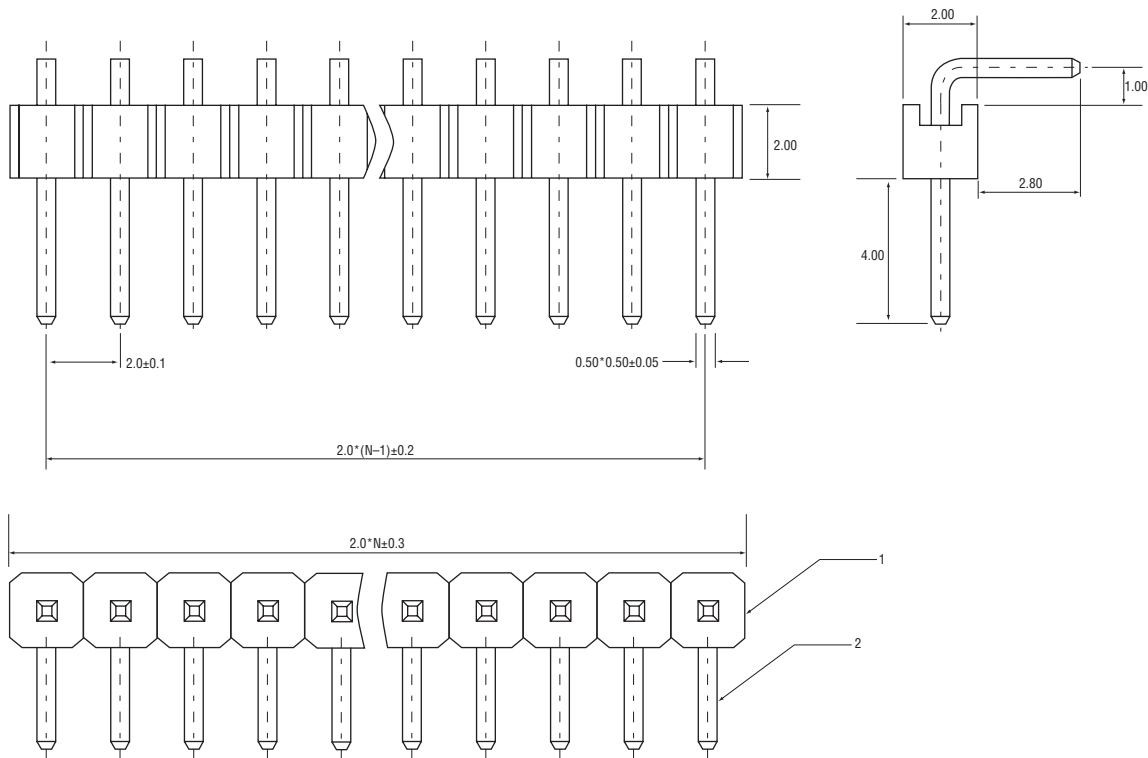

N: Number of contacts
A&B&C: Customer length available

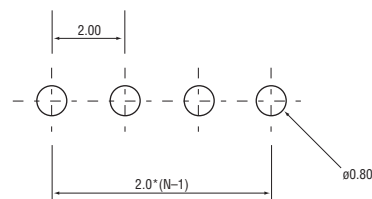

www.rapidonline.com