



40-way Double Row Right Angled PCB Header Plug – 2mm Pitch

Order code: 19-0079

Notes:


1. Material

- 1.1 Insulator: Thermoplastic (UL 94V-0)
- 1.2 Contact material: Copper alloy



2. Specification

- 2.1 Current rating: 1.5 Amp
- 2.2 Insulation resistance: 1000M Ω min.
- 2.3 Dielectric withstanding: 600VAC
- 2.4 Contact resistance: 20m Ω max.
- 2.5 Operating temperature: -20°C to +80°C

No.	Description	Material	Plating
1	Housing	Thermoplastic	UL 94 V-0
2	Contact	Copper Alloy	Gold flash

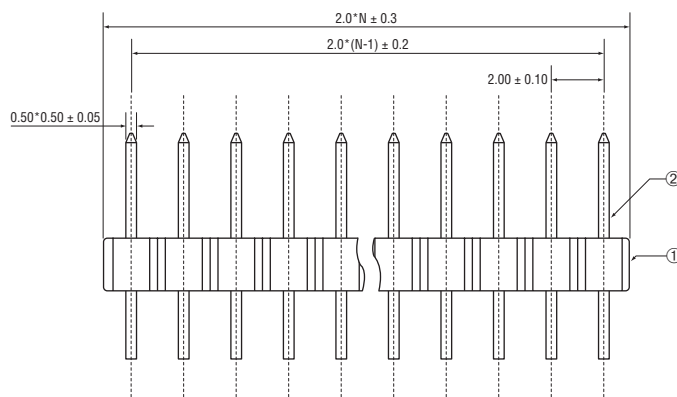

N: Number of contacts/2

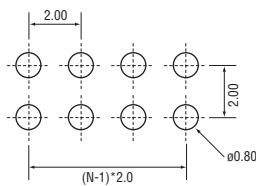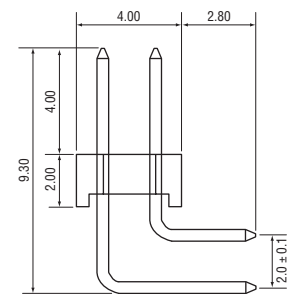

RECOMMEND PCB LAYOUT (Tolerance + ± 0.05)