


NOTE:

- CABLE:UL2725,USB 2.0,AL+B-FOIL,#28\*1P+#28\*2C,BLACK COLOR,OD=4.0±0.2mm,PVC JACKET.
- LENGTH: 1.8M.
- CONNECTORS:USB4P(A)TYPE PLUG\*1(WHITE INSULATOR)(PIN 3U'').  
MICRO USBM 5P\*1(BLACK INSULATOR)(PIN 3U'').
- MOLD:MOLDING USB TYPE.
- CONTACTS:  

USB4P(A)	1	2	3	4	64
	RED	WHITE	GREEN	BLACK	DRAIN

MICRO USB5P	1	2	3	5	64
	PAIR				
- Test machine test condition.  
 A.100% OPEN,SHORT&INTERMITANCE TEST.  
 B.CONDUCTOR RESISTANCE:3ohms MAX;  
 C.INSULATION RESISTANCE:5M Min/,10ms;
- ALL MUST BE MEET ON ROHS COMPLIANT.

ITEN NO	COLOR	LENGTH
CDL-160	BLACK	1.8M
CDL-160BG	BEIGE	1.8M

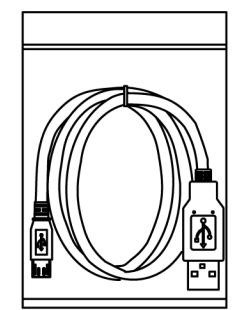

COMPANY	CDL		ITEM NO.	CDL-160	NO	B5732			SCALE	NON
REVISION	DATE	DISCRIPTION	DRAWN BY		SPEC				UNIT(mm)	
REV.A/0	2010.08.30	A10-1008011	DESIGNED BY						PAGE	1/1
REV.A/1	2011.04.16	修正线材OD=4.0	APPROVAL BY							
REV.A/2	2011.12.13	C9-1111009								