


## DC Power Jack Adaptor

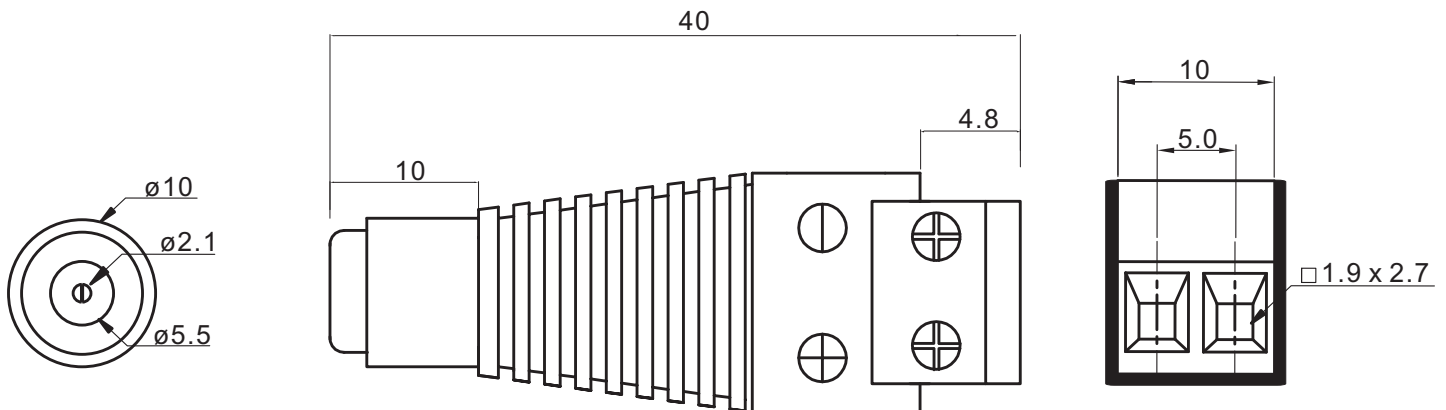

### Technical Data:

#### Electrical:

Voltage rating: 12VDC

Current rating: 5A

Contact resistance: 20mΩ

Insulation resistance: 5000MΩ / 1000V

Wire range: 26-14AWG

#### Mechanical:

Torque: 0.4Nm (3.5lb/in)

Operating temperature: -40°C to 105°C

Strip length: 6mm

(All dimensions are in mm)