

 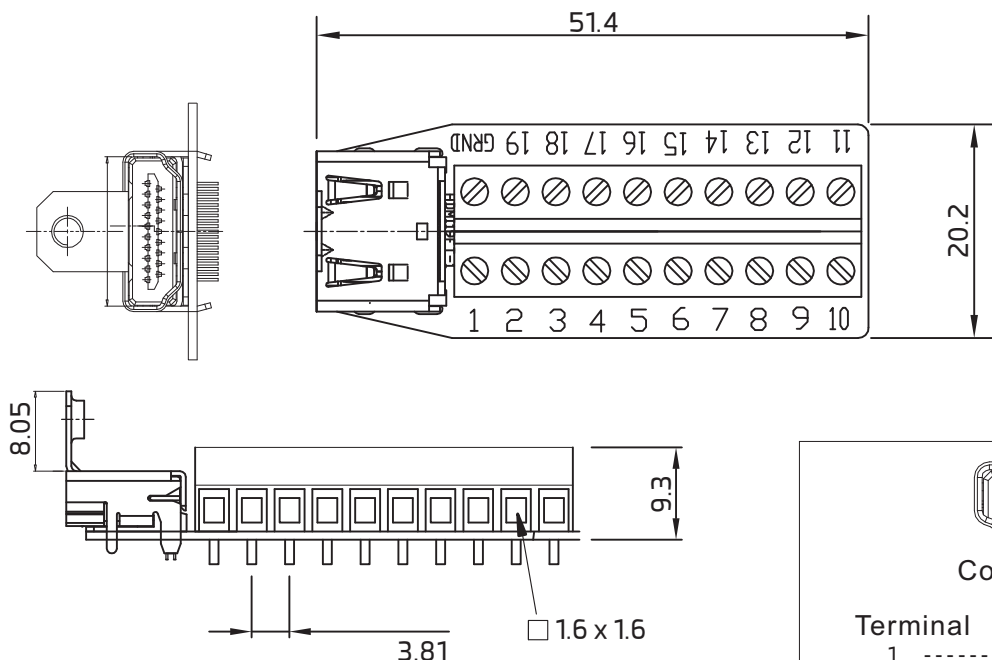


HDMI Terminal Block Adaptor Type A, Receptacle, 20 PIN

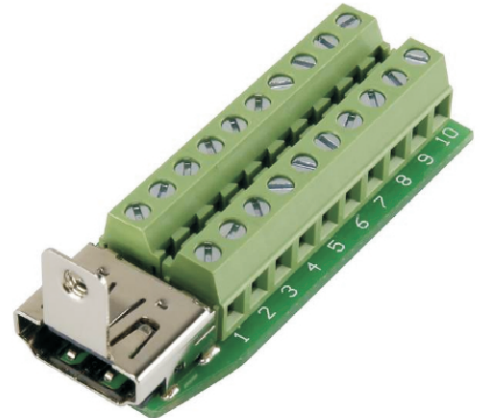

Technical Data:

Voltage rating: 40VDC
Current rating: 0.5A
Contact resistance: 30mΩ max.
Insulation resistance: 100MΩ / 500VDC
Wire range: 16-30AWG
Operating temperature: -40°C to 105°C



Connect information

Terminal	HDMI
1	1 TMDS Data2+
2	2 TMDS Data2 Shield
3	3 TMDS Data2-
4	4 TMDS Data1+
5	5 TMDS Data1 Shield
6	6 TMDS Data1-
7	7 TMDS Data0+
8	8 TMDS Data0 Shield
9	9 TMDS Data0-
10	10 TMDS Clock+
11	11 TMDS Clock Shield
12	12 TMDS Clock-
13	13 CEC
14	14 Reserved (N.C. on device)
15	15 SCL(I ² C serial clock for DDC)
16	16 SDA(I ² C serial data for DDC)
17	17 DDC/CEC Ground
18	18 +5 V Power
19	19 Hot Plug Detect
GRND	shell