

45 degree PCB


Order code	Manufacturer code	Description
21-0130	645TDS02	2 WAY 45 DEG 16A TERMINAL BLOCK
21-0132	645TDS03	3 WAY 45 DEG 16A TERMINAL BLOCK
21-0134	645TDS04	4 WAY 45 DEG 16A TERMINAL BLOCK
21-0136	645TDS06	6 WAY 45 DEG 16A TERMINAL BLOCK

45 degree PCB	Page 1 of 2
The enclosed information is believed to be correct, Information may change 'without notice' due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E.	Revision A 04/07/2003

SERIES 645TDS

5MM PITCH-45 DEGREE- RISING CLAMP

3

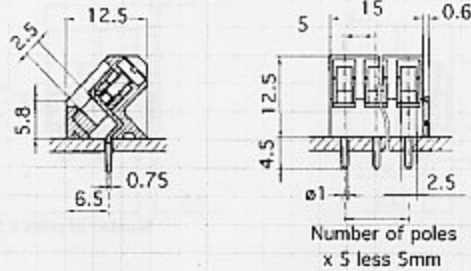

metway
CONNECT

Printed Circuit
Terminal Blocks

KARSON
TECHNOLOGY

TECHNICAL DATA

Mouldings:	Polycarbonate, UL94 V0 Grey
Inserts & solder pins:	Brass, tinned to ISO 2093
Screws:	M2.5, steel zinc plated and passivated
Wire protectors:	Bronze, nickel plated
Current rating:	16 amps
Conductor size:	2.5 mm sq.
Maximum working temp:	120°C

FEATURES

Series 645T are 5mm pitch, 45 degree entry connectors and are available in 2 and 3 pole versions which have interlocking dovetails to enable longer lengths to be assembled. Supplied as 2 and 3 pole modules, or to pre-assembled required lengths.


OPTIONS

Marking: Special printing available please provide sketch

Pin spacing: Available in 10mm pitch type 646T

Colour: Also available in colours black and blue

APPROVALS

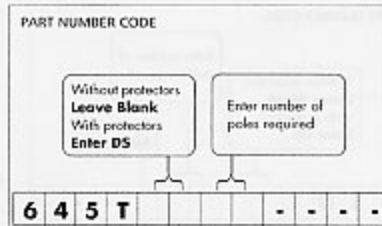

01273 439266

01273 439288

sales@metway.co.uk