


## DESTB-0252

2 Pole steatite ceramic high temperature blocks terminal 32a 450v

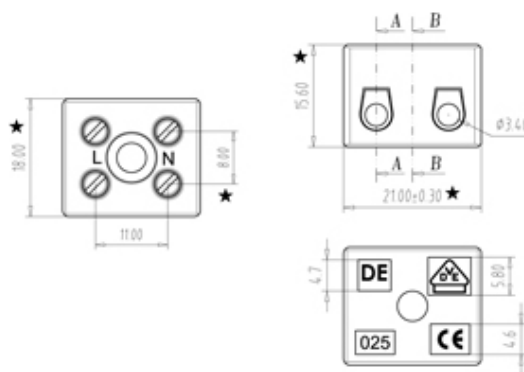

### SPECIFICATION

Number of Poles	2
Body Material	Steatite
Colour	White
Min Conductor Size (Sq mm)	1.5
Max Conductor Size (Sq mm)	6
Min Conductor Size AWG	22
Max Conductor Size AWG	12
Max Current (A)	32
Max Voltage (V)	450
Minimum Temp Rating °C	-40
Max Temp Rating °C	300-350
Pitch (mm)	11
Height (mm)	15.6
Width (mm)	18
Length (mm)	21
Comments	M3 conductor clamping screws, maximum torque=0.5Nm

### DISTRIBUTORS

