


7.62mm Header Right Angle Open 15A Terminal Blocks

Specifications

Pitch:	7.62mm
Type:	90°, Open-ended
Poles:	2 to 12
Rated Voltage:	See Table
Rated Current:	See Table
Operational Temperature:	-40°C to +105°C
Withstand Voltage:	2500V AC for 60s
Insulation Resistance:	500MΩ at 500V DC
Wave Soldering:	260°C for 5s
Hand Soldering:	350°C for 10s



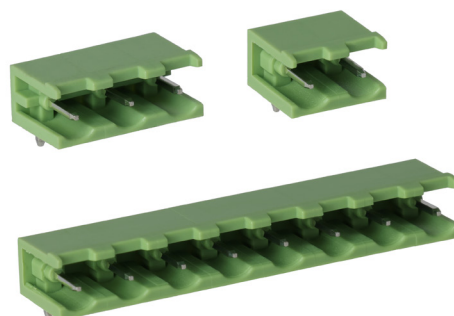


Colour and Materials

Housing Colour:	Green
Housing Material:	PA66
Flame Retardancy:	UL94-V0
Pin Header:	Tin-plated brass

Order Code	Poles	Order Code	Poles
21-1865	2	21-1870	8
21-1866	3	21-1998	9
21-1867	4	21-1871	10
21-1868	5	21-1999	11
21-1869	6	21-1872	12
21-1997	7		

Standard	Rated Voltage	Rated Current
UL	300V	15A
IEC	400V	20A

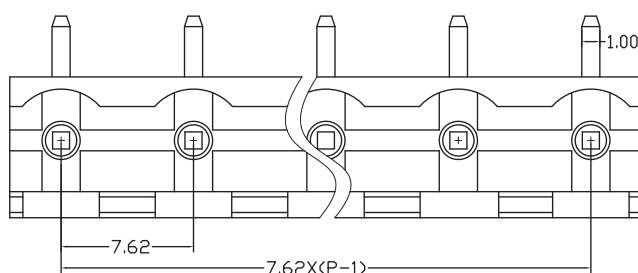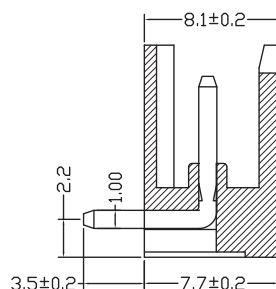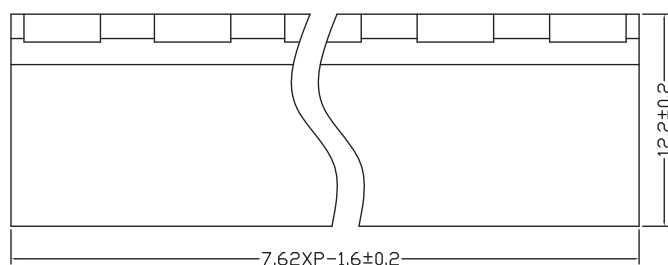

Measurements are in mm
unless stated otherwise.

