


7.62mm Header Right Angle Closed 15A Terminal Blocks

Specifications

Pitch:	7.62mm
Type:	90°, Closed-ended
Poles:	2 to 12
Rated Voltage:	See Table
Rated Current:	See Table
Operational Temperature:	−40°C to +105°C
Withstand Voltage:	2500V AC for 60s
Insulation Resistance:	500MΩ at 500V DC
Wave Soldering:	260°C for 5s
Hand Soldering:	350°C for 10s




Colour and Materials

Housing Colour:	Green
Housing Material:	PA66
Flame Retardancy:	UL94-V0
Pin Header:	Tin-plated brass

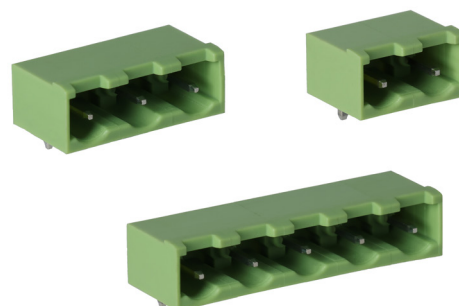

Order Code	Poles	Order Code	Poles
21-1881	2	21-1886	8
21-1882	3	21-2002	9
21-1883	4	21-1887	10
21-1884	5	21-2003	11
21-1885	6	21-1888	12
21-2001	7		

Standard	Rated Voltage	Rated Current
UL	300V	15A
IEC	400V	20A

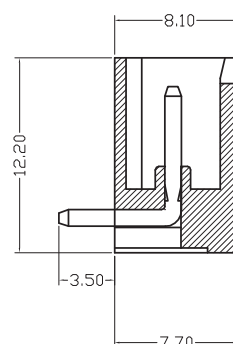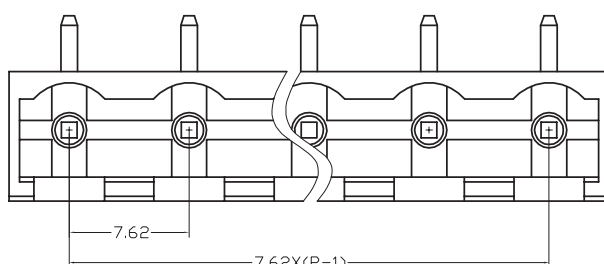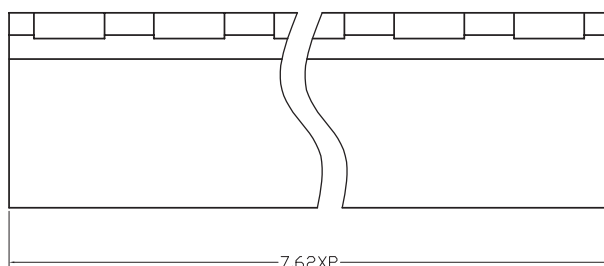

Measurements are in mm
unless stated otherwise.

For further information on pricing, delivery, and long-term stock agreements please get in touch with your local business development contact. Telephone our main office on **01206 838000** or email **Sales@Rapidonline.com**.

The information contained in this datasheet is subject to change without notice and replaces all data sheets previously supplied.

