


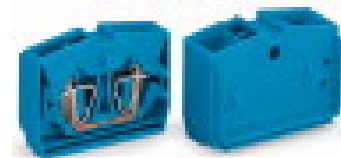

4-conductor end terminal block; with fixing flange; for screw or similar mounting types; Fixing hole 3.2 mm Ø; suitable for Ex i applications

Item No.: 264-334



4-conductor end terminal block; with fixing flange; for screw or similar mounting types; Fixing hole 3.2 mm Ø; suitable for Ex i applications

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	264-334
GTIN / EAN	4044918414609
Content	1

Notes

Technical data

Miscellaneous


Rated voltage (III / 3) [V]	800 [V]
Rated impulse voltage (III / 3) [kV]	8 [kV]
Rated current [A]	24 [A]
Legend (ratings)	(III / 3) Overvoltage category III / Pollution degree 3

Printview: 4-conductor end terminal block; with fixing flange; for screw or similar mounting types; Fixing hole 3.2 mm Ø; suitable for Ex i applications - Item No.: 264-334

Technical data	
Type of wiring	Front-entry wiring
Total number of connection points	4
Total number of potentials	1
Number of levels	1
Connection technology	CAGE CLAMP®
Actuation type	Operating tool
Connectable conductor materials	Copper
Solid conductor	0.08 ... 2.5 mm ² / 28 ... 12 AWG
Fine-stranded conductor	0.08 ... 2.5 mm ² / 28 ... 12 AWG
Strip length	8 ... 9 mm / 0.31 ... 0.35 Inch
Note (conductor cross-section)	12 AWG: THHN, THWN
Width	10 mm / 0.394 Inch
Height from the surface	22.1 mm / 0.87 Inch
Depth	32 mm / 1.26 Inch
Design	horizontal
Mounting type	Mounting flange
Marking level	Center marking
Color	blue
Fire load [MJ]	0.109 [MJ]
Weight [g]	6.26 [g]
Main product function	Through term. block
Product type	Miniature rail-mount terminal blocks

Printview: 4-conductor end terminal block; with fixing flange; for screw or similar mounting types; Fixing hole 3.2 mm Ø; suitable for Ex i applications - Item No.: 264-334

Images & drawings

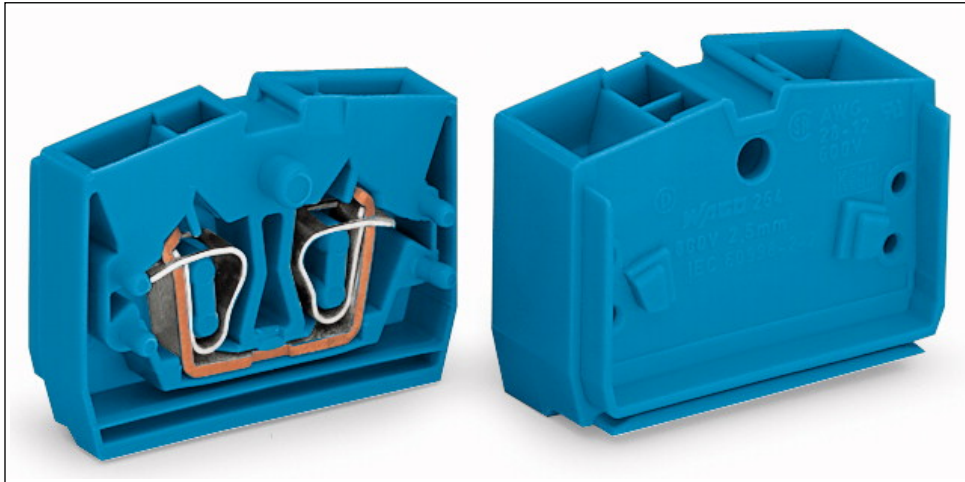

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.