




## Component module with resistor; with 8 pcs; Resistor 2K2; 1 Watt

Item No.: 289-113

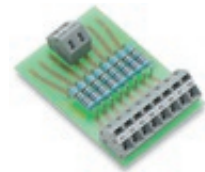

Component module with resistor; with 8 pcs; Resistor 2K2; 1 Watt

### Marking

RoHS ✓  
Compliant

### Business data

|            |               |
|------------|---------------|
| Supplier   | WAGO          |
| Item no.   | 289-113       |
| GTIN / EAN | 4045454192785 |
| Content    | 1             |
|            |               |
|            |               |

### Notes

*Note: Max. admissible capacity of a single resistor. With all resistors loaded, the max. admissible power dissipation must be reduced.*

*For other resistors, please contact factory!*


### Technical data


#### Miscellaneous


|                         |  |
|-------------------------|--|
|                         |  |
| Connection technology   | CAGE CLAMP®                                  |
| Solid conductor         | 0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG |
| Fine-stranded conductor | 0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG |

| <b>Technical data</b>                        |  |
|--|--|
| <i>Strip length</i>                          | <i>5 ... 6 mm / 0.2 ... 0.24 Inch</i>                    |
| <i>Connection technology 1</i>               | <i>WAGO 236 Series</i>                                   |
| <i>Width</i>                                 | <i>47 mm / 1.85 Inch</i>                                 |
| <i>Height from upper-edge of DIN-35 rail</i> | <i>31.5 mm / 1.24 Inch</i>                               |
| <i>Depth</i>                                 | <i>65.5 mm / 2.579 Inch</i>                              |
| <i>Type of mounting</i>                      | <i>Mounting on carrier rail via carrier rail adapter</i> |
| <i>Fire load [MJ]</i>                        | <i>0.738 [MJ]</i>  |
| <i>Weight [g]</i>                            | <i>18.915 [g]</i>  |
| <i>Ambient temperature (operation)</i>       | <i>-25 ... 40 °C</i>                                     |
| <i>Housing design</i>                        | <i>PCB</i>   |
| <i>Main product function</i>                 | <i>Resistor module</i>                                   |
| <i>Product type</i>                          | <i>Specialty electronics</i>                             |

Images & drawings

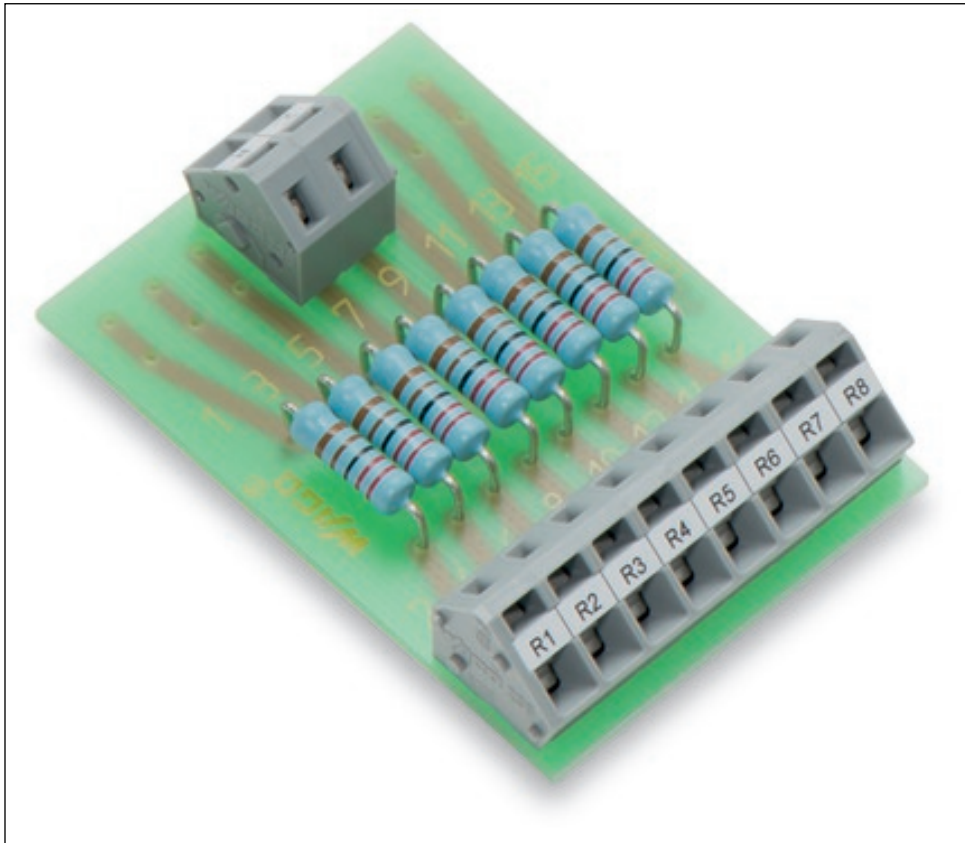

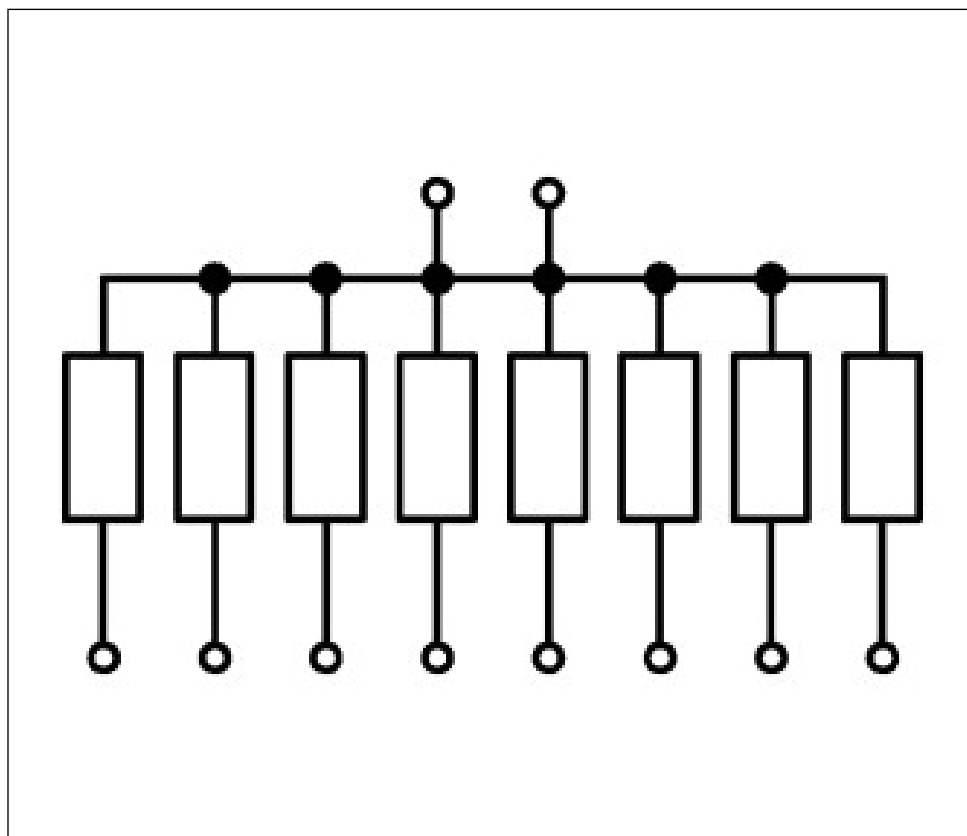

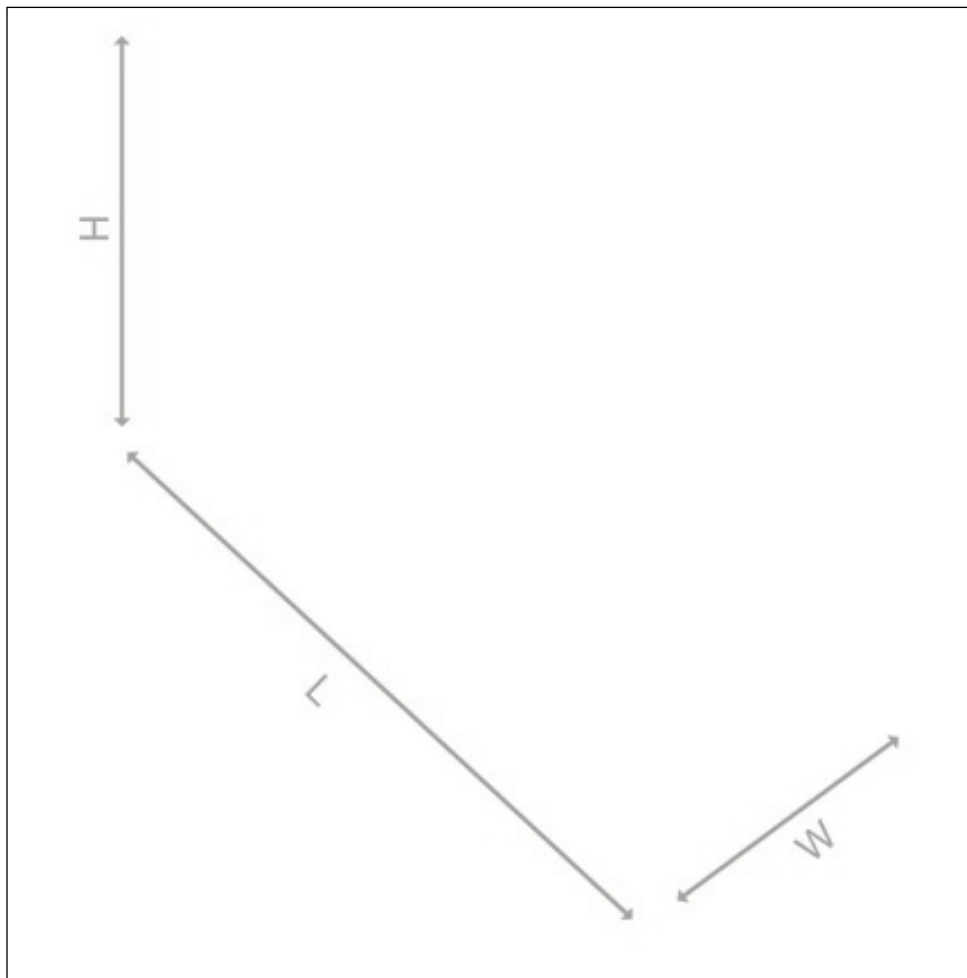

**Address**

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.