



**Interface module; with D-subminiature male connector; 50-pole;
for mating connectors with IDC; Vertical mounting**

Item No.: 289-444



Interface module; with D-subminiature male connector; 50-pole; for mating connectors with IDC; Vertical mounting

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	289-444
GTIN / EAN	4045454599416
Content	1

Notes

** Notice! Live conductors! Protection against direct contact must be provided by the equipment builder, e.g., using a WAGO 709 Series cover (see Accessories) or a similar cover. The installation requirements for the particular application must be observed.*



Technical data


Miscellaneous


No. of poles	50
Connection type (1)	Connectors

Technical data	
Connection technology	Connectors
Connection type (2)	PCB terminal blocks
Connection technology 2	CAGE CLAMP®
Solid conductor (2)	0.08 ... 2.5 mm ² / 28 ... 12 AWG
Fine-stranded conductor (2)	0.08 ... 2.5 mm ² / 28 ... 12 AWG
Strip length (2)	5 ... 6 mm / 0.2 ... 0.24 Inch
Wire connection 2	WAGO 236 Series
Pull relief stud bolt	UNC 4-40
Width	157 mm / 6.181 Inch
Height from upper-edge of DIN-35 rail	19 mm / 0.748 Inch
Depth	63.5 mm / 2.5 Inch
Type of mounting	DIN-35 rail
Degree of protection	IP00*
Connector contact	Au over Ni
Fire load [MJ]	0.7 [MJ]
Weight [g]	102.5 [g]
Ambient temperature (operation)	-20 ... 50 °C
Ambient temperature (storage)	-40 ... 70 °C
Relative humidity	max. 85 % (nicht betauend)
Pollution degree	2
Housing design	PCB with mounting feet
Main product function	Interface module with Sub-D/Sub-H-D contact
Product type	Universal module

Images & drawings

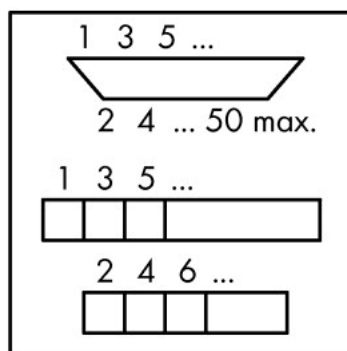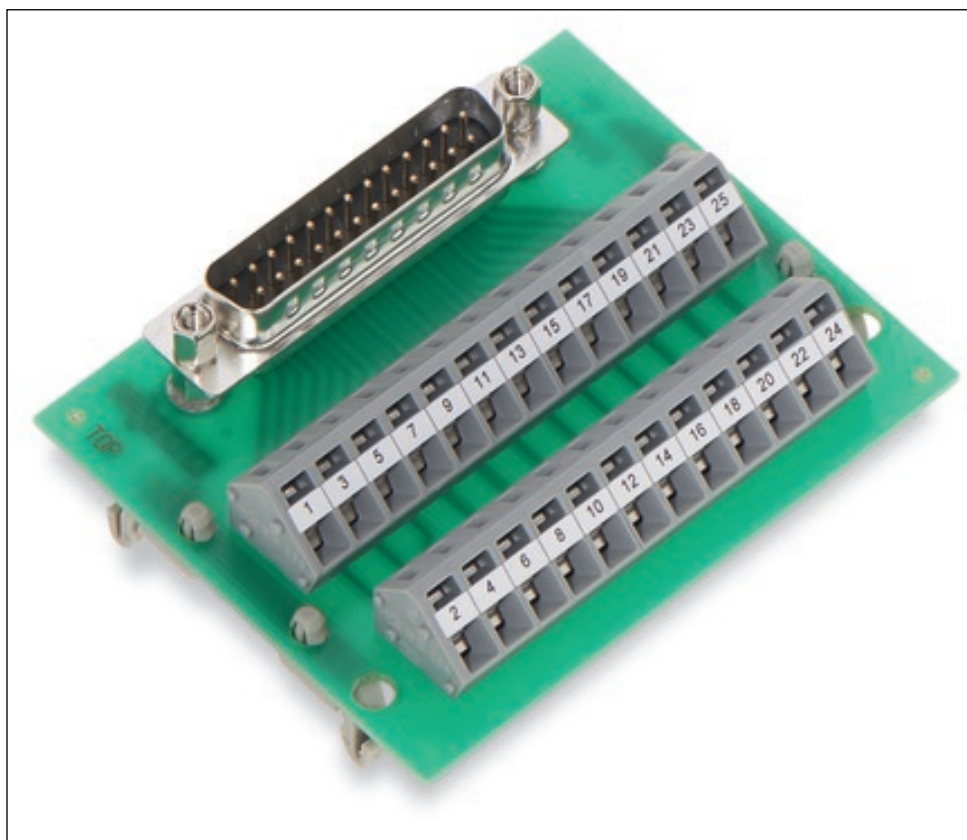

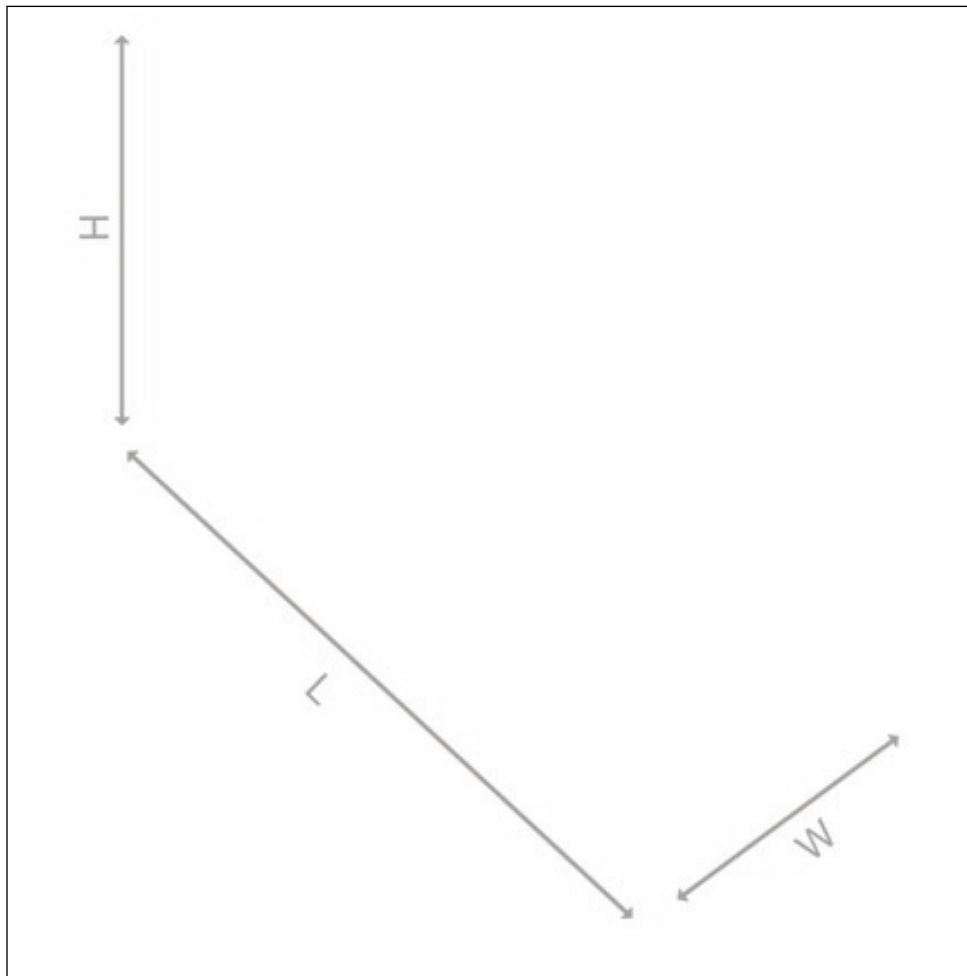

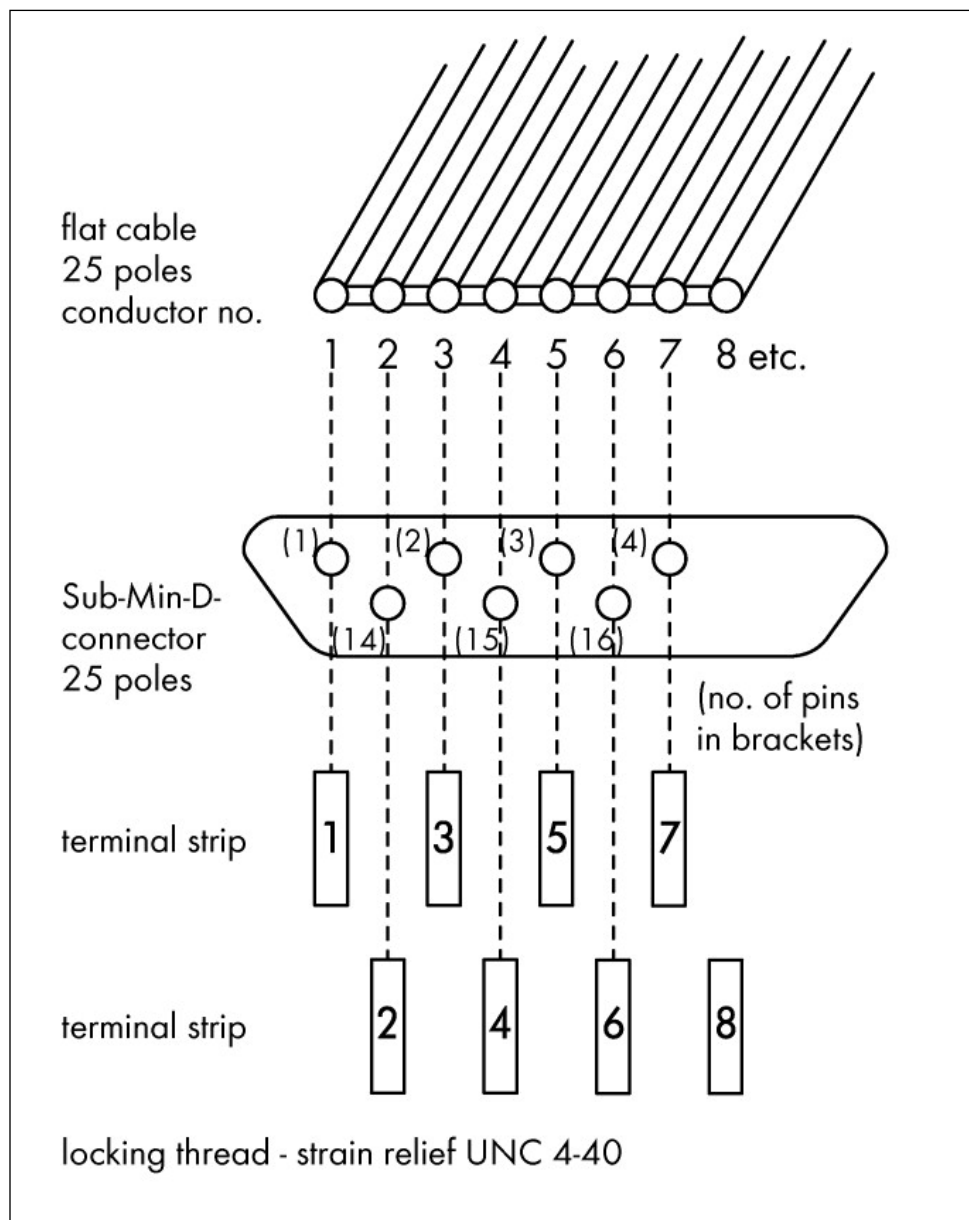

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.