



Interface module; with male connector; 64-pole; Type C; for female connector with IDC; for connectors per DIN 41612; Horizontal mounting

Item No.: 289-523



Interface module; with male connector; 64-pole; Type C; for female connector with IDC; for connectors per DIN 41612; Horizontal mounting

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	289-523
GTIN / EAN	4045454594183
Content	1

Notes

* Notice! Live conductors! Protection against direct contact must be provided by the equipment builder, e.g., using a WAGO 709 Series cover (see Accessories) or a similar cover. The installation requirements for the particular application must be observed.



Technical data


Miscellaneous

No. of poles	64

Technical data	
Connection type (1)	Connectors
Connection technology	Connectors
Connection type (2)	PCB terminal blocks
Connection technology 2	CAGE CLAMP®
Solid conductor (2)	0.08 ... 2.5 mm ² / 28 ... 12 AWG
Fine-stranded conductor (2)	0.08 ... 2.5 mm ² / 28 ... 12 AWG
Strip length (2)	5 ... 6 mm / 0.2 ... 0.24 Inch
Wire connection 2	WAGO 236 Series
Width	171 mm / 6.732 Inch
Height from upper-edge of DIN-35 rail	34 mm / 1.339 Inch
Depth	85 mm / 3.346 Inch
Type of mounting	DIN-35 rail
Degree of protection	IP00*
Connector contact	Copper alloy, gold plated
Fire load [MJ]	2.527 [MJ]
Weight [g]	159.3 [g]
Ambient temperature (operation)	-20 ... 50 °C
Ambient temperature (storage)	-40 ... 70 °C
Relative humidity	max. 85 % (nicht betauend)
Pollution degree	2
Housing design	Mounting carrier
Main product function	Interface module for pluggable connectors (DIN 41612)
Product type	Universal module

Images & drawings

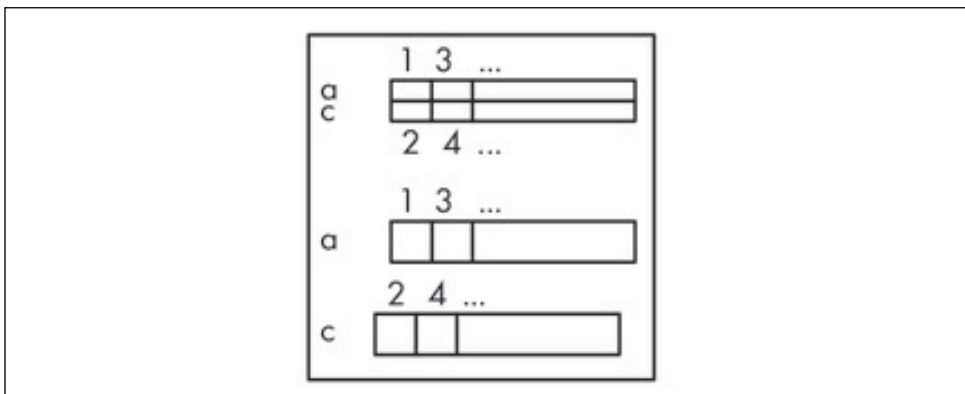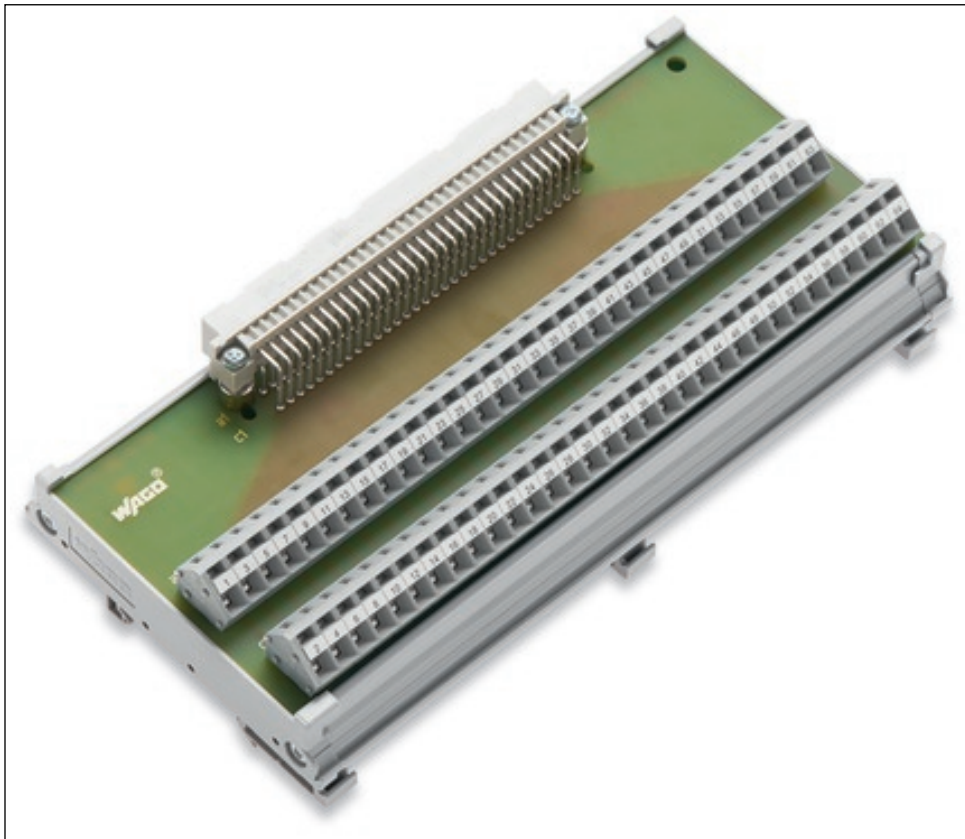

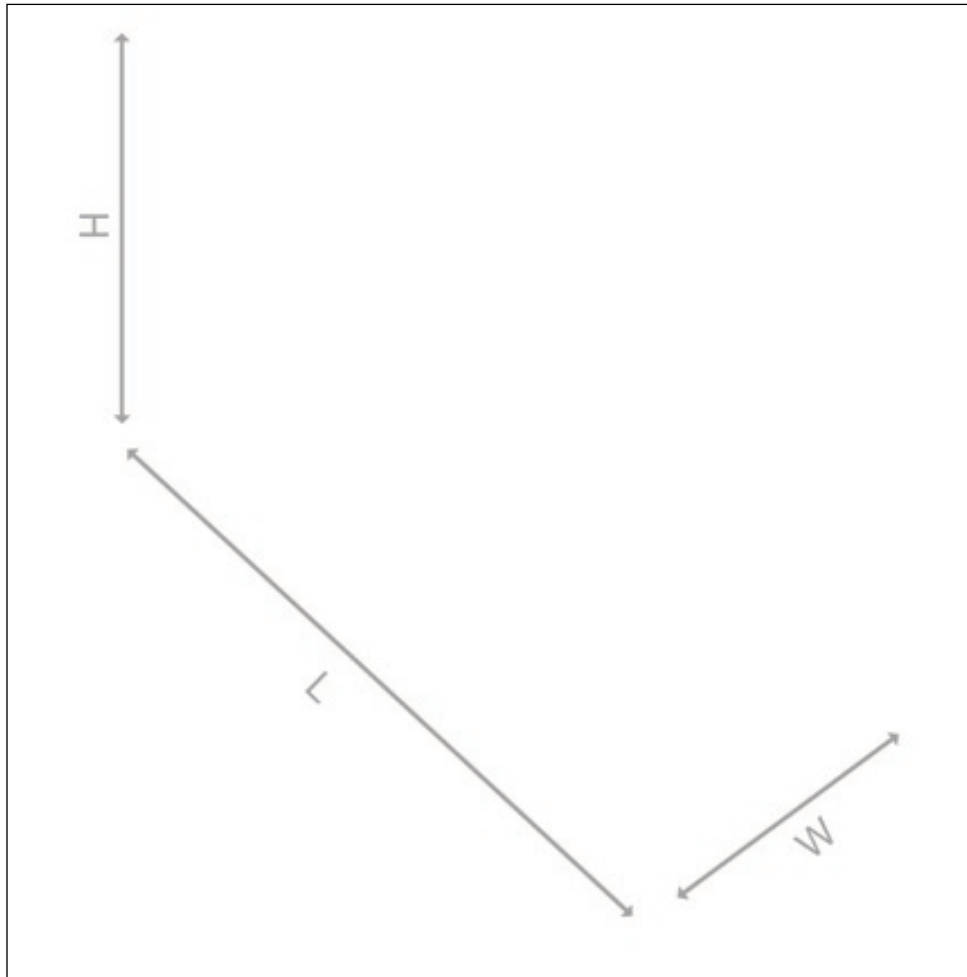

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.