




## Connection module; for 8 3-conductor sensors

Item No.: 289-664

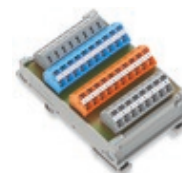

Connection module; for 8 3-conductor sensors

### Marking

RoHS   
Compliant

### Business data

Supplier	WAGO
Item no.	289-664
GTIN / EAN	4045454193294
Content	1

### Notes


### Technical data


#### Miscellaneous


Connection technology	CAGE CLAMP®
Solid conductor	0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG
Fine-stranded conductor	0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG
Strip length	5 ... 6 mm / 0.2 ... 0.24 Inch
Connection technology 1	WAGO 236 Series

<b>Technical data</b>	
<i>Width</i>	<i>56 mm / 2.205 Inch</i>
<i>Height from upper-edge of DIN-35 rail</i>	<i>34 mm / 1.339 Inch</i>
<i>Depth</i>	<i>85 mm / 3.346 Inch</i>
<i>Type of mounting</i>	<i>DIN-35 rail</i>
<i>Fire load [MJ]</i>	<i>1.248 [MJ]</i>
<i>Weight [g]</i>	<i>73.013 [g]</i>
<i>Ambient temperature (operation)</i>	<i>-20 ... 50 °C</i>
<i>Ambient temperature (storage)</i>	<i>-40 ... 70 °C</i>
<i>Relative humidity</i>	<i>max. 85 % (nicht betauend)</i>
<i>Pollution degree</i>	<i>2</i>
<i>Housing design</i>	<i>Mounting carrier</i>
<i>Main product function</i>	<i>Interface module for actuators and sensors</i>
<i>Product type</i>	<i>Universal module</i>

Images & drawings

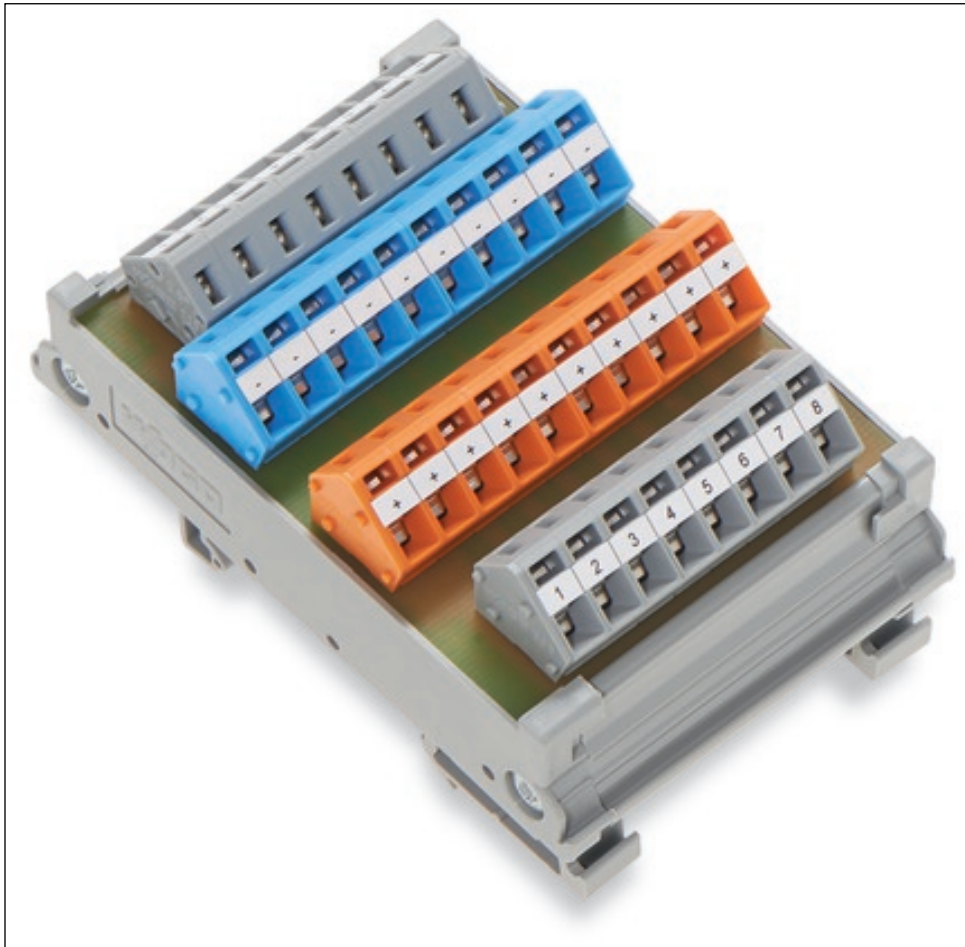

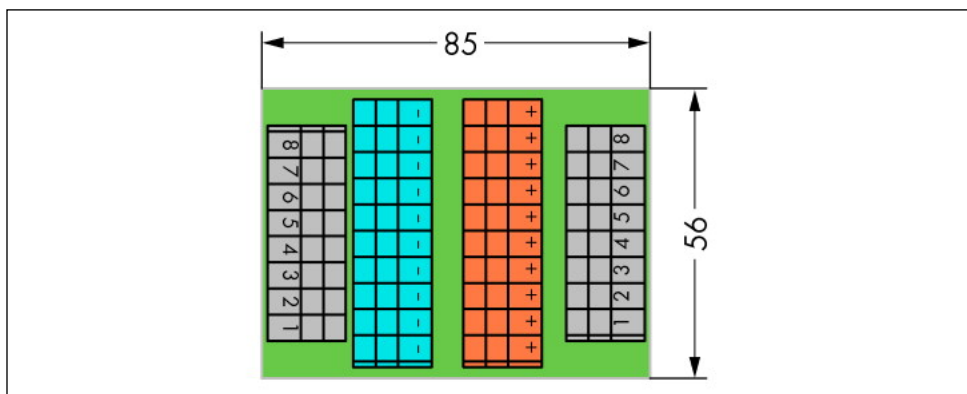

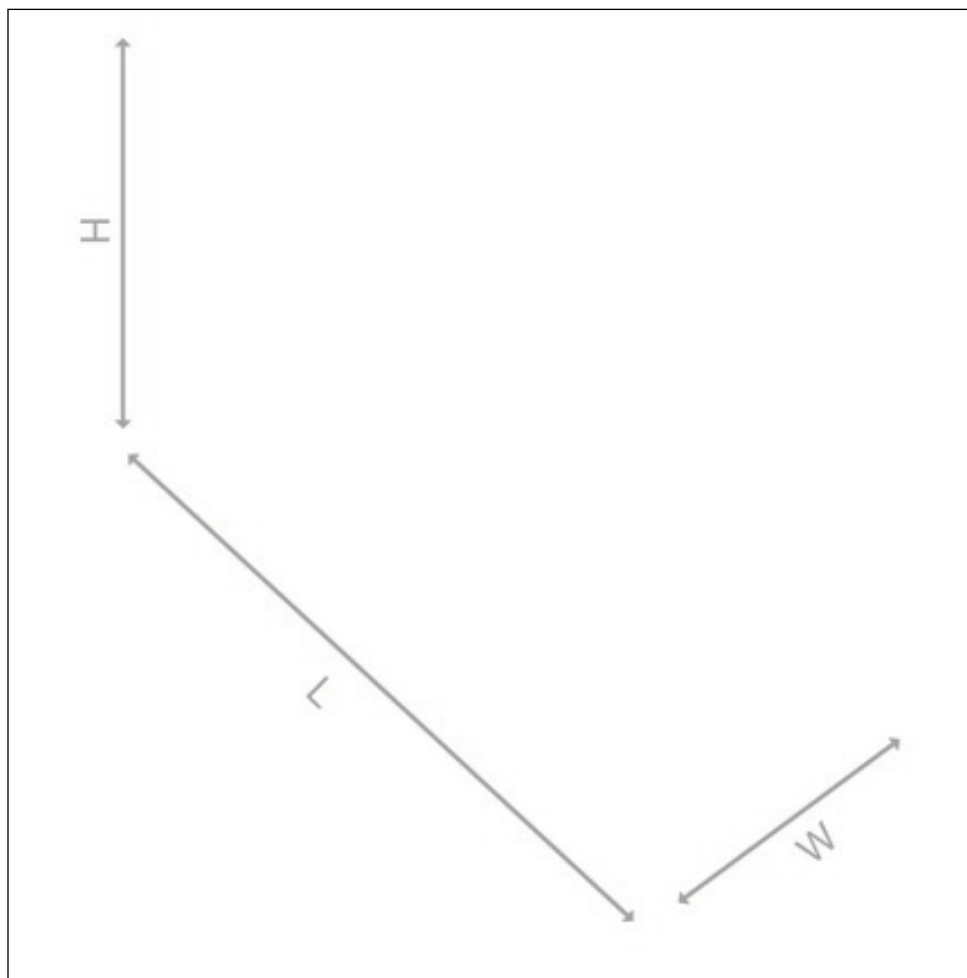

**Address**

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.