


Data sheet | Item number: 706-753/301-100

Connection cable; 16-pole; Pluggable connector per DIN 41651; 16-pole; Pluggable connector per DIN 41651; Length: 1 m (1 MOhm); Conductor cross-section: 0.14 mm²

www.wago.com/706-753/301-100

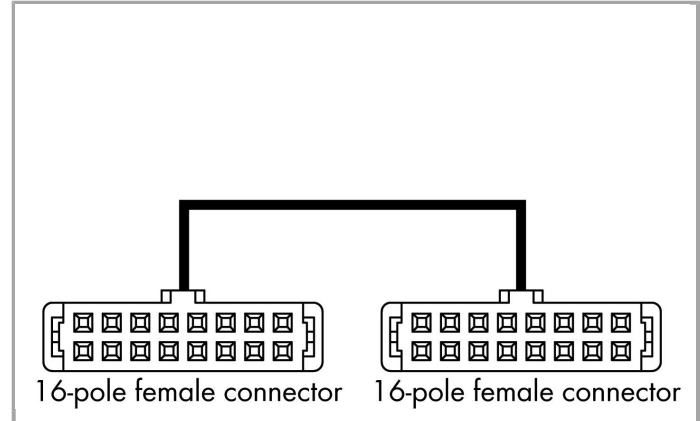

RoHS Compliant

BOMcheck.net

Item description

Short description:

WAGO's 16-Pole Interface Cables transmit signals one-to-one from the 16-pole pluggable connector and are available in 1-, 2- and 3-meter lengths. Signal transmission from the 857-980 Interface Adapter is also possible.

Suitable for system wiring when paired with WAGO's Interface Adapter (857-980)

Data

Electrical data

Operating voltage	≤ 35 VDC
Max. current per conductor	1 A

Safety and protection:

Degree of protection	IP20
----------------------	------

Connection data

No. of poles	16
Connection type (1)	System



No. of poles 1	16
Pluggable connector	Pluggable connector per DIN 41651; female connector
Connection type (2)	System
No. of poles 2	16
Pluggable connector 2	Pluggable connector per DIN 41651; female connector
Type of cable	LIYY
Cross section of single conductor	0.14 mm ²
Color coding	per DIN VDE 47100

Geometrical Data

Cable length	1 m
--------------	-----

Material Data

Weight	9.999 g
--------	---------

Environmental Requirements

Surrounding air (operating) temperature	-25 ... 70 °C
---	---------------

Subject to changes.