



Strain relief housing; 4-pole; Cable diameter 5 - 9 mm

Item No.: 770-504/023-000



Strain relief housing; 4-pole; Cable diameter 5 - 9 mm

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	770-504/023-000
GTIN / EAN	4045454341756
Content	1

Notes

Note on Continuous Service Temperature:-35°C to +85°CInsulating parts for temperatures 105°C


Technical data

Miscellaneous

No. of poles	4
Connectable sheathed cable diameter	5 ... 9 mm
Width	44.6 mm / 1.756 Inch
Height	17 mm / 0.669 Inch
Depth	50 mm / 1.969 Inch

Technical data	
Degree of protection	IP20
Color	black
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0
Fire load [MJ]	0.337 [MJ]
Weight [g]	12.94 [g]
Ambient temperature (operation)	-35 ... 85 °C
Processing temperature	-5°C ... +40°C
Product Family	WINSTA MIDI
Main product function	Strain relief housing
Product type	Accessories

Images & drawings

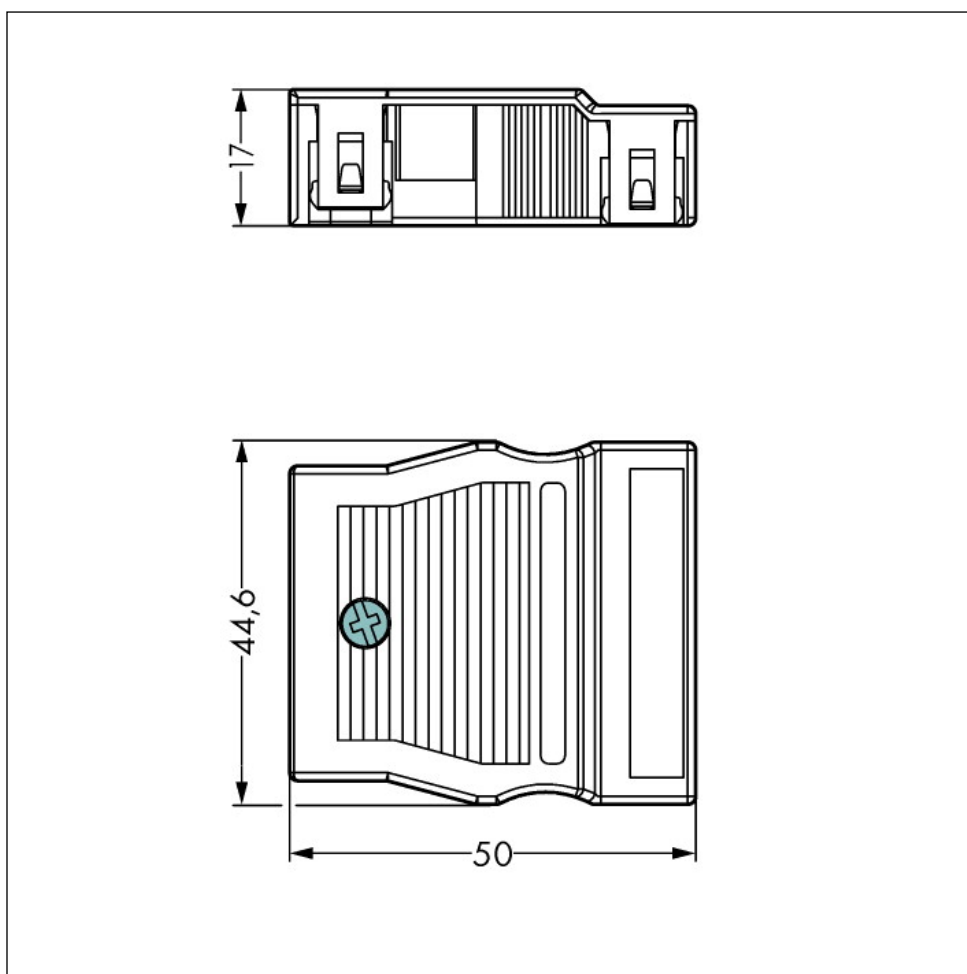

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.