



COMPACT PUSH WIRE® connector for junction boxes; 3-conductor terminal block; transparent housing; orange cover

Item No.: 2273-203



COMPACT PUSH WIRE® connector for junction boxes; 3-conductor terminal block; transparent housing; orange cover

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	2273-203
GTIN / EAN	4050821027850
Content	1

Notes

Technical data


Miscellaneous

Safety information 1	In grounded power lines
Ratings per	IEC/EN 60664-1
Rated voltage (II / 2) [V]	450 [V]
Rated impulse voltage (II / 2) [kV]	4 [kV]

Technical data	
<i>Rated current [A]</i>	24 [A]
<i>Legend (ratings)</i>	(II / 2) Overvoltage category II / Pollution degree 2
<i>Type of wiring</i>	Side-entry wiring
<i>Total number of connection points</i>	3
<i>Total number of potentials</i>	1
<i>Connection technology</i>	PUSH WIRE®
<i>Actuation type</i>	Push-in
<i>Connectable conductor materials</i>	Copper
<i>Solid conductor</i>	0.5 ... 2.5 mm ² / 18 ... 14 AWG
<i>Strip length</i>	11 mm / 0.43 Inch
<i>Width</i>	14 mm / 0.551 Inch
<i>Height</i>	5.8 mm / 0.228 Inch
<i>Depth</i>	16.7 mm / 0.657 Inch
<i>Color</i>	orange
<i>Cover color</i>	orange
<i>Flammability class per UL94</i>	V2
<i>Fire load [MJ]</i>	0.019 [MJ]
<i>Weight [g]</i>	1.017 [g]
<i>Ambient temperature (operation)</i>	60 °C
<i>Continuous operating temperature up to [°C]</i>	105 [°C]
<i>T-Marking per EN 60998</i>	T60
<i>Main product function</i>	Steckklemme
<i>Product type</i>	Splicing connectors

Images & drawings



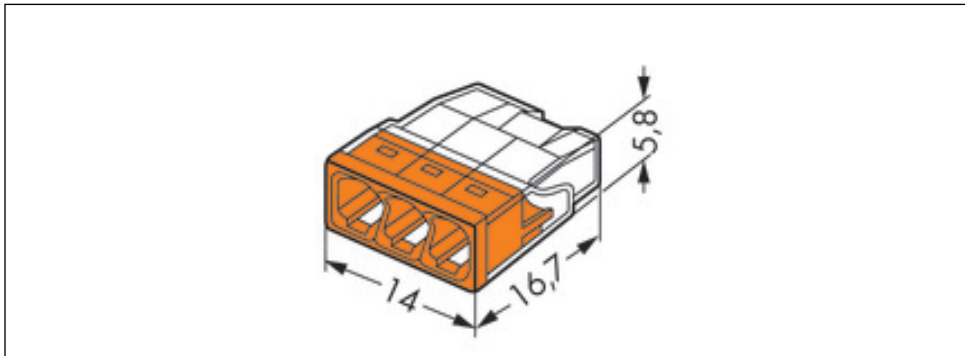

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.