



MICRO PUSH WIRE® connector for junction boxes; 4-conductor terminal block

Item No.: 243-504



MICRO PUSH WIRE® connector for junction boxes; 4-conductor terminal block

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	243-504
GTIN / EAN	4044918440813
Content	1

Notes

Safety information 1: When using conductors of the same diameter, Ø 0.5 mm / 24 AWG or Ø 1 mm / 18 AWG are also possible.

Technical data


Miscellaneous

Rated voltage (II / 2) [V]	100 [V]
Rated impulse voltage (II / 2) [kV]	1.5 [kV]
Rated current [A]	6 [A]

Technical data	
Legend (ratings)	(II / 2) Overvoltage category II / Pollution degree 2
Type of wiring	Side-entry wiring
Total number of connection points	4
Total number of potentials	1
Number of connection types	1
Number of levels	1
Connection technology	PUSH WIRE®
Actuation type	Push-in
Connectable conductor materials	Copper
Conductor diameter	0.6 ... 0.8 mm / ... AWG
Strip length	5 ... 6 mm / 0.2 ... 0.24 Inch
Width	10 mm / 0.394 Inch
Height	6.8 mm / 0.268 Inch
Depth	10 mm / 0.394 Inch
Color	yellow
Fire load [MJ]	0.011 [MJ]
Weight [g]	0.76 [g]
Ambient temperature (operation)	60 °C
Continuous operating temperature up to [°C]	105 [°C]
Main product function	Steckklemme
Product type	Splicing connectors

Images & drawings



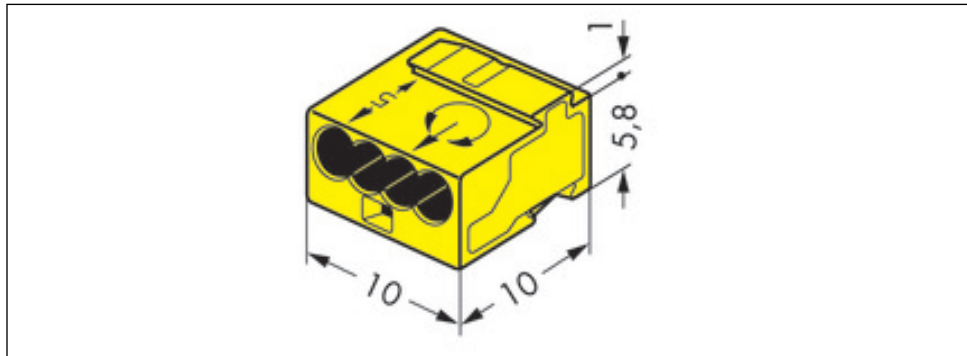

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.