



Empty housing

Item No.: 2857-102



Empty housing

Marking

RoHS
Compliant

Business data

Supplier	WAGO
Item no.	2857-102
GTIN / EAN	4050821561408
Content	1

Notes

Item description: Features: picoMAX® female connectors, with coding keys, 2-pole Pre-assembled unit Flexible conductor termination Customization of connection levels Various marking options available Sealable, transparent cover Commoning option via 859-402 jumpers

Technical data


Miscellaneous

Packaging type	BOX
No. of poles	2
Number of levels	3
Number of jumper slots	2

Technical data	
<i>Connection technology</i>	<i>Push-in CAGE CLAMP®</i>
<i>Solid conductor</i>	<i>0.2 ... 2.5 mm² / 24 ... 12 AWG</i>
<i>Fine-stranded conductor</i>	<i>0.2 ... 2.5 mm² / 24 ... 12 AWG</i>
<i>Fine-stranded conductor with ferrule with plastic collar</i>	<i>0.2 ... 1.5 mm² / 24 ... 16 AWG</i>
<i>Strip length</i>	<i>9 ... 10 mm / 0.35 ... 0.39 Inch</i>
<i>Width</i>	<i>12.5 mm / 0.492 Inch</i>
<i>Height</i>	<i>107 mm / 4.213 Inch</i>
<i>Depth</i>	<i>110 mm / 4.331 Inch</i>
<i>Pin spacing</i>	<i>5 mm (0.197 in)</i>
<i>Type of mounting</i>	<i>DIN-35 rail</i>
<i>Flammability class per UL94</i>	<i>V0</i>
<i>Housing material</i>	<i>PC</i>
<i>Clamping spring material</i>	<i>Chrome nickel spring steel (CrNi)</i>
<i>Contact material</i>	<i>Electrolytic copper (Ecu)</i>
<i>Fire load [MJ]</i>	<i>1.684 [MJ]</i>
<i>Weight [g]</i>	<i>62.959 [g]</i>
<i>Ambient temperature (operation)</i>	<i>-40 ... 70 °C</i>
<i>Ambient temperature (storage)</i>	<i>-40 ... 85 °C</i>
<i>Housing design</i>	<i>Modular Housing</i>
<i>Main product function</i>	<i>Empty housings, modular</i>
<i>Product type</i>	<i>Empty housings</i>

Images & drawings



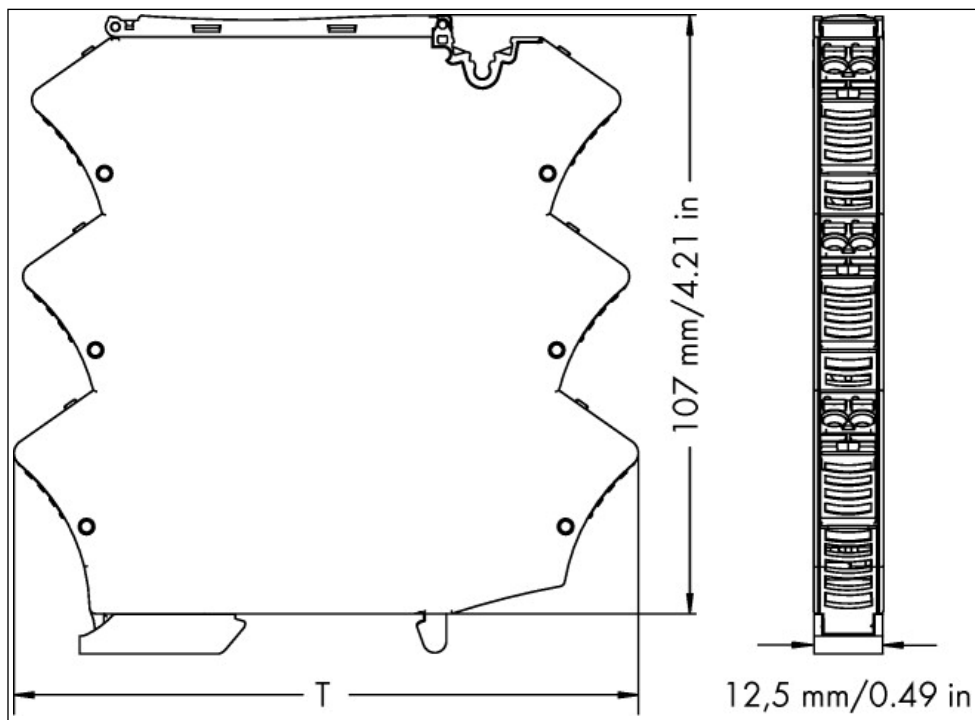



Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.