



## Component module with resistor; with 8 pcs; Resistor 2K7; 0.6 Watt

Item No.: 289-114



Component module with resistor; with 8 pcs; Resistor 2K7; 0.6 Watt

### Marking

RoHS   
Compliant

### Business data

Supplier	WAGO
Item no.	289-114
GTIN / EAN	4045454192938
Content	1

### Notes

*Note: Max. admissible capacity of a single resistor. With all resistors loaded, the max. admissible power dissipation must be reduced.*

*For other resistors, please contact factory!*


### Technical data


#### Miscellaneous


Connection technology	CAGE CLAMP®
Solid conductor	0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG
Fine-stranded conductor	0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG

<b>Technical data</b>	
<i>Strip length</i>	<i>5 ... 6 mm / 0.2 ... 0.24 Inch</i>
<i>Connection technology 1</i>	<i>WAGO 236 Series</i>
<i>Width</i>	<i>47 mm / 1.85 Inch</i>
<i>Height from upper-edge of DIN-35 rail</i>	<i>31.5 mm / 1.24 Inch</i>
<i>Depth</i>	<i>65.5 mm / 2.579 Inch</i>
<i>Type of mounting</i>	<i>Mounting on carrier rail via carrier rail adapter</i>
<i>Fire load [MJ]</i>	<i>0.802 [MJ]</i>
<i>Weight [g]</i>	<i>23.38 [g]</i>
<i>Ambient temperature (operation)</i>	<i>-25 ... 40 °C</i>
<i>Housing design</i>	<i>PCB</i>
<i>Main product function</i>	<i>Resistor module</i>
<i>Product type</i>	<i>Specialty electronics</i>

Images & drawings

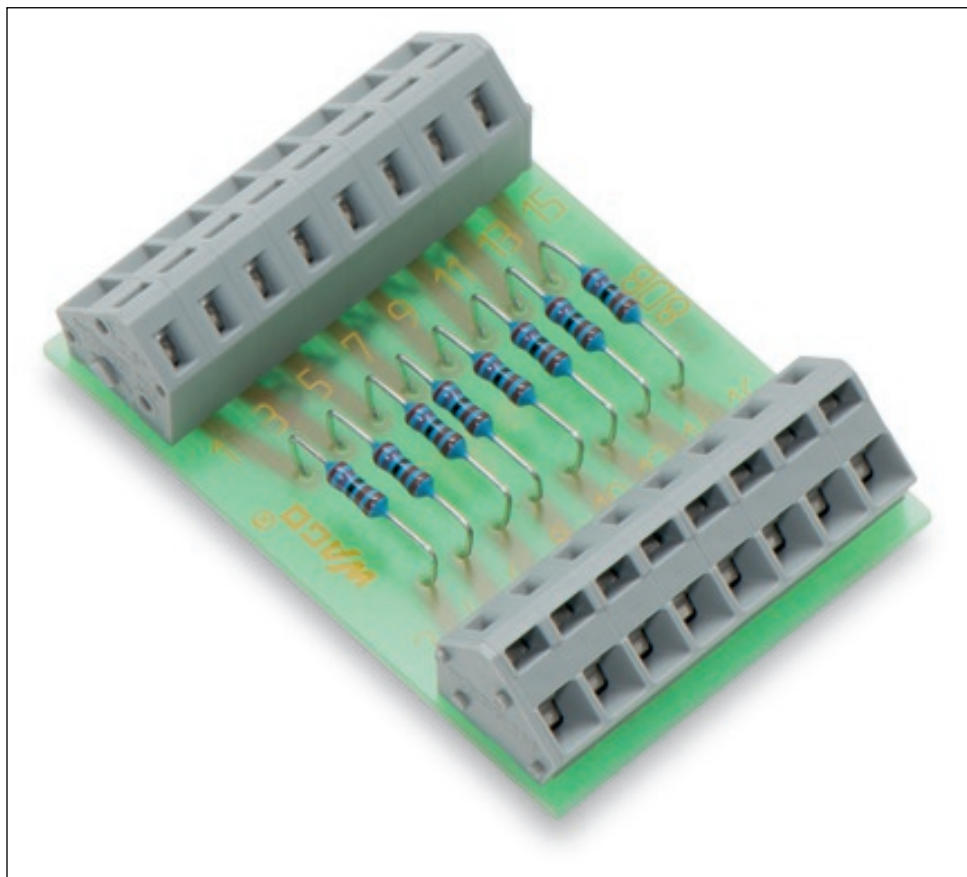

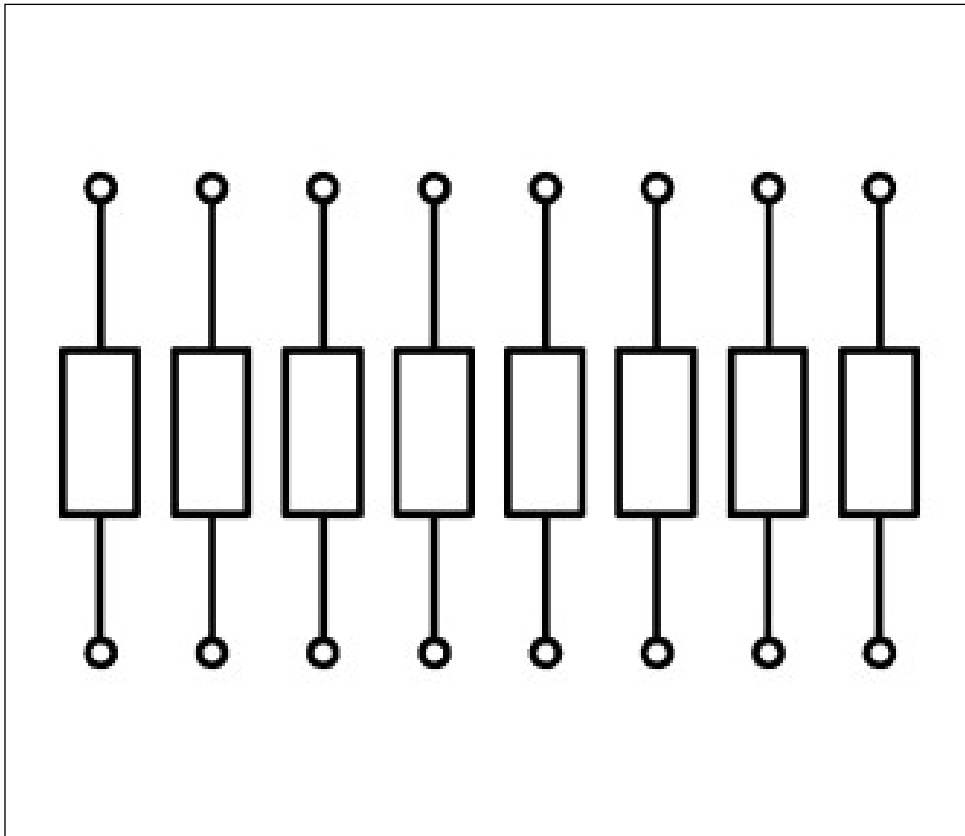

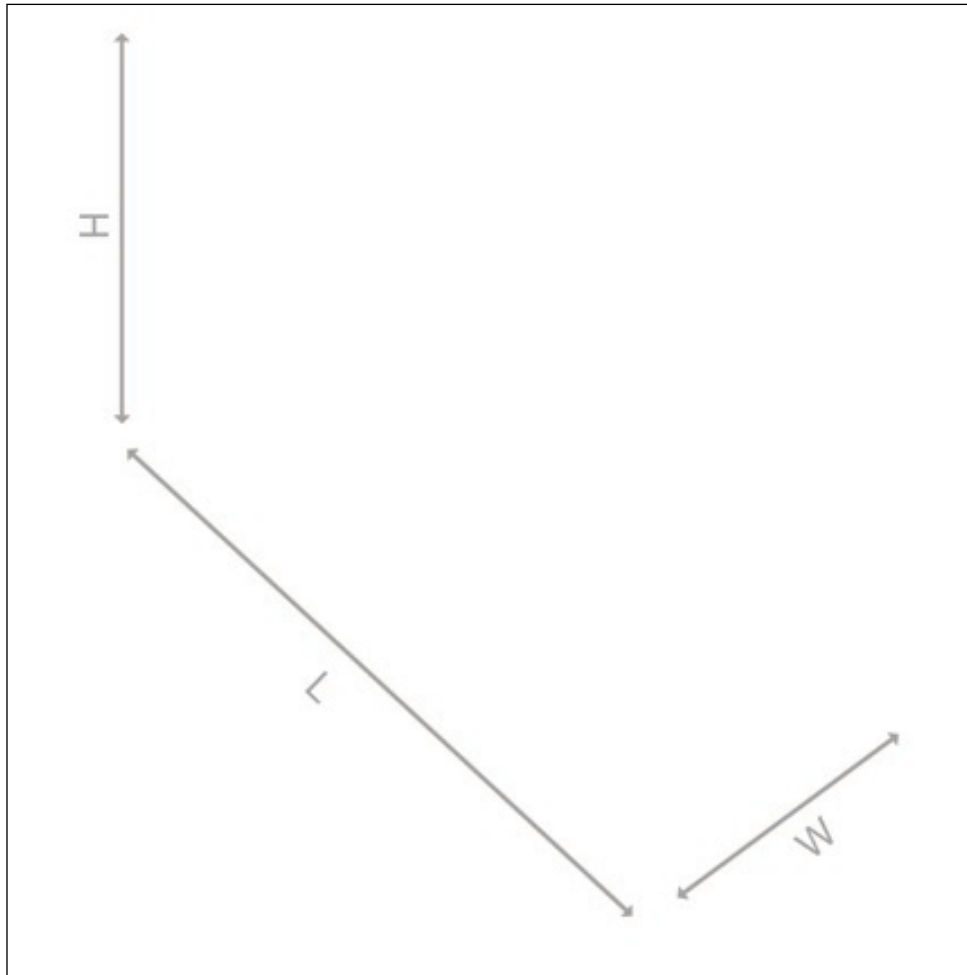

**Address**

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.