



Interface module for ETHERNET RJ-45

Item No.: 289-174



Interface module for ETHERNET RJ-45

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	289-174
GTIN / EAN	4045454317492
Content	1

Notes


Technical data



Miscellaneous

Connection type (1)	Connectors
Connection technology	Connectors
Connection type (2)	PCB terminal blocks
Connection technology 2	CAGE CLAMP®
Solid conductor (2)	0.08 ... 1.5 mm² / 28 ... 14 AWG

Technical data	
<i>Fine-stranded conductor (2)</i>	<i>0.08 ... 1.5 mm² / 28 ... 14 AWG</i>
<i>Strip length (2)</i>	<i>5 ... 6 mm / 0.2 ... 0.24 Inch</i>
<i>Wire connection 2</i>	<i>WAGO 739 Series</i>
<i>Connector</i>	<i>RJ-45 shielded</i>
<i>Min. mating cycles</i>	<i>500</i>
<i>Width</i>	<i>24 mm / 0.945 Inch</i>
<i>Height from upper-edge of DIN-35 rail</i>	<i>40 mm / 1.575 Inch</i>
<i>Depth</i>	<i>85 mm / 3.346 Inch</i>
<i>Type of mounting</i>	<i>DIN-35 rail</i>
<i>Fire load [MJ]</i>	<i>0.58 [MJ]</i>
<i>Weight [g]</i>	<i>32.6 [g]</i>
<i>Ambient operating temperature</i>	<i>-40 °C ... +85 °C (Actuation: -35 °C ... +85 °C)</i>
<i>Ambient temperature (operation)</i>	<i>-40 ... 85 °C</i>
<i>Relative humidity</i>	<i>max. 85 % (nicht betauend)</i>
<i>Standards/specifications</i>	<i>ISO/IEC 11801: 2002-09; EN 55022</i>
<i>Housing design</i>	<i>Mounting carrier</i>
<i>Main product function</i>	<i>Interface module for RJ-45 pluggable connectors</i>
<i>Product type</i>	<i>Universal module</i>

Images & drawings

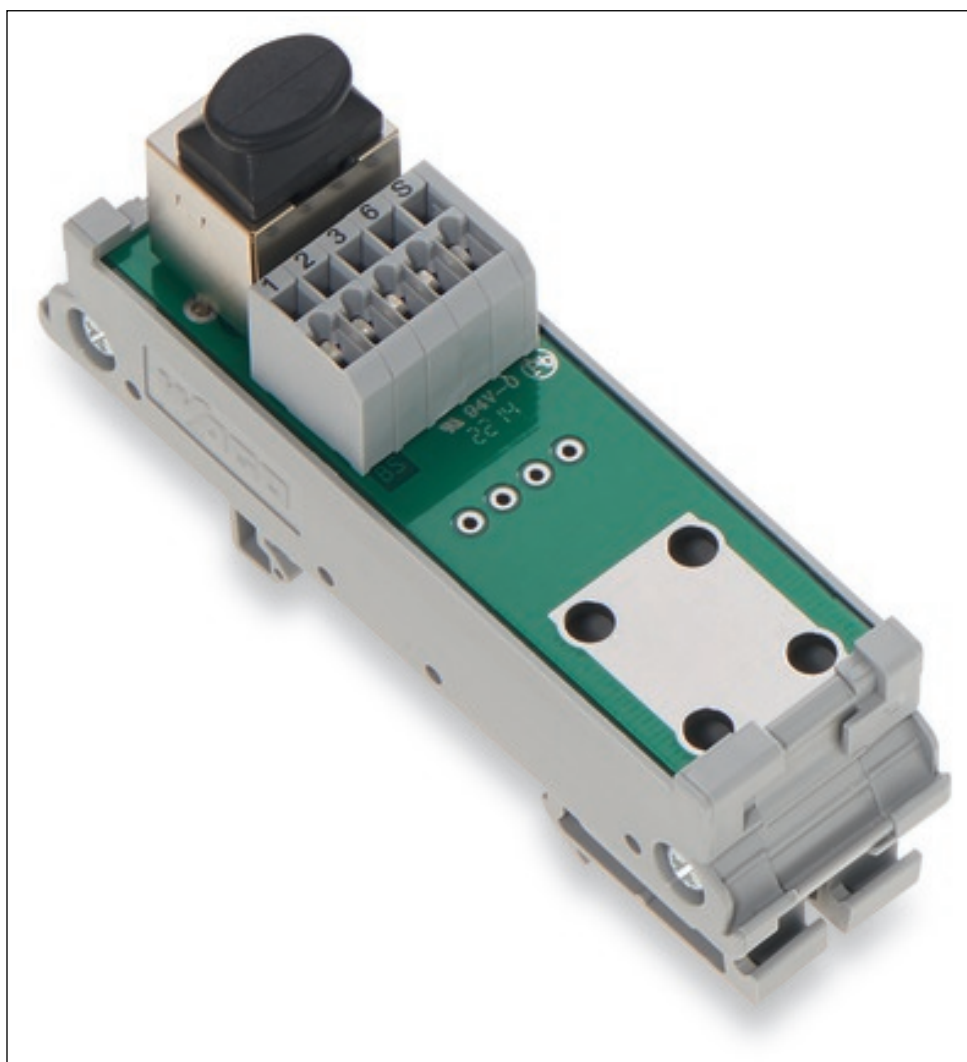

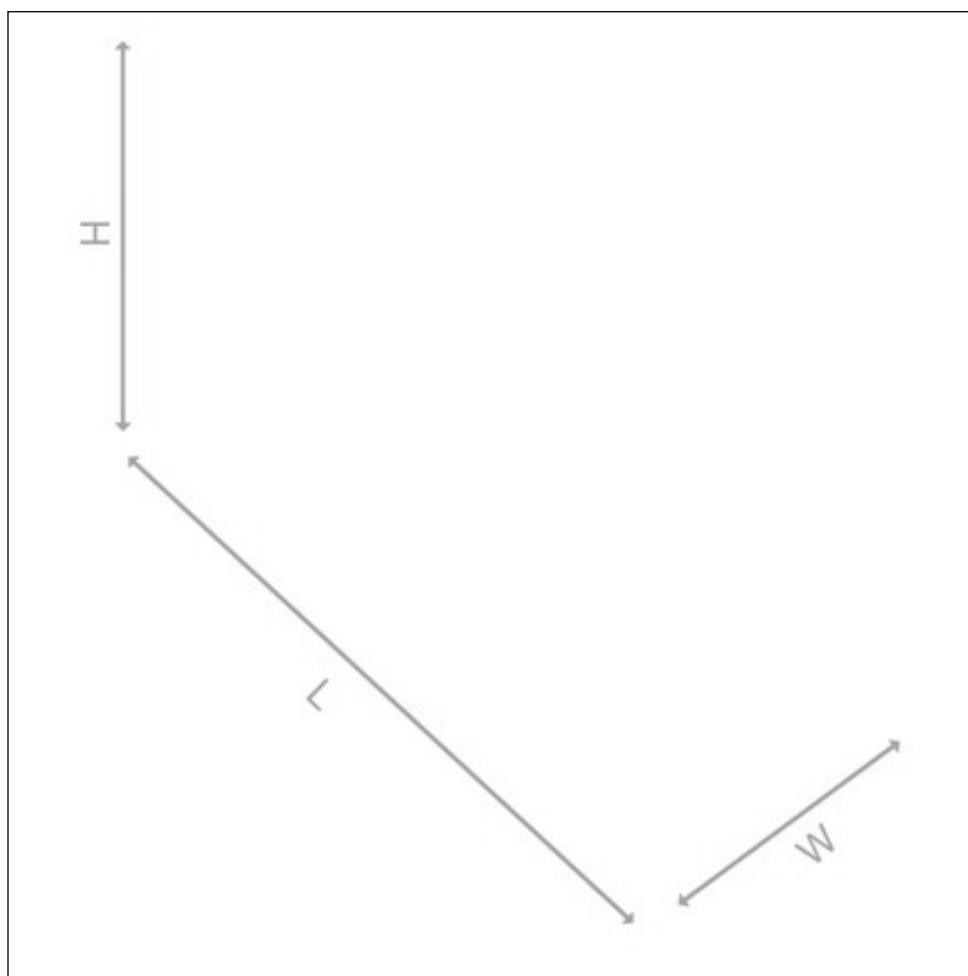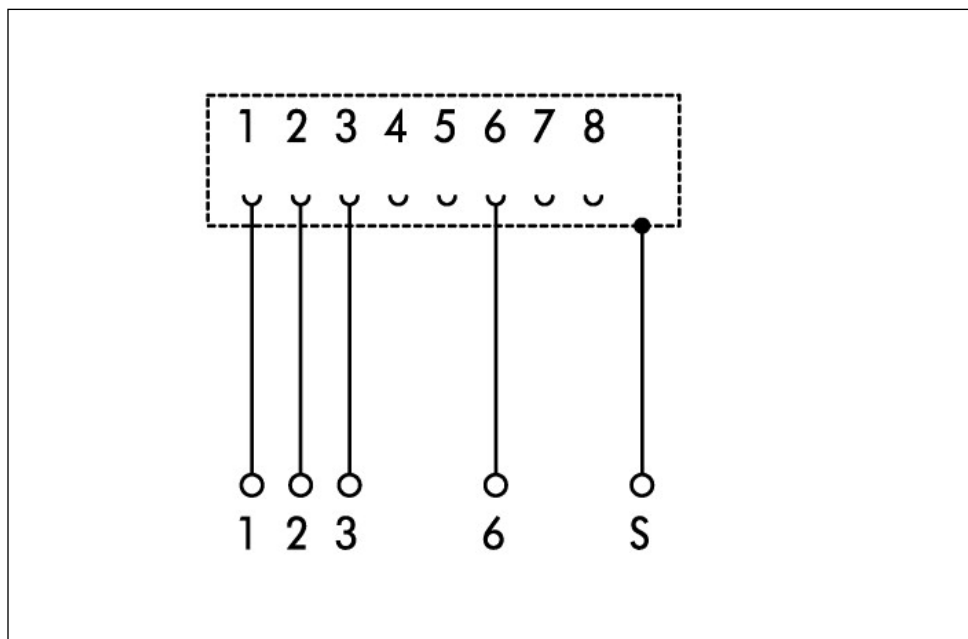

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.