



## Interface module; with male connector per DIN 41651; 20-pole

Item No.: 289-404



Interface module; with male connector per DIN 41651; 20-pole

### Marking

RoHS ✓  
Compliant

### Business data

Supplier	WAGO
Item no.	289-404
GTIN / EAN	4045454783112
Content	1

### Notes

\* Notice! Live conductors! Protection against direct contact must be provided by the equipment builder, e.g., using a WAGO 709 Series cover (see Accessories) or a similar cover. The installation requirements for the particular application must be observed.



### Technical data


#### Miscellaneous

No. of poles	20
Connection type (1)	Connectors
Connection technology	Connectors

<b>Technical data</b>	
Connection type (2)	PCB terminal blocks
Connection technology 2	CAGE CLAMP®
Solid conductor (2)	0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG
Fine-stranded conductor (2)	0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG
Strip length (2)	5 ... 6 mm / 0.2 ... 0.24 Inch
Wire connection 2	WAGO 236 Series
Width	66.5 mm / 2.618 Inch
Height from upper-edge of DIN-35 rail	28 mm / 1.102 Inch
Depth	63.5 mm / 2.5 Inch
Type of mounting	DIN-35 rail
Degree of protection	IP00*
Connector contact	Au over Ni
Fire load [MJ]	0.304 [MJ]
Weight [g]	40 [g]
Ambient temperature (operation)	-20 ... 55 °C
Ambient temperature (storage)	-40 ... 70 °C
Relative humidity	max. 85 % (nicht betauend)
Pollution degree	2
Housing design	PCB with mounting feet
Main product function	Interface module for pluggable connectors (DIN 41651)
Product type	Universal module

Images & drawings

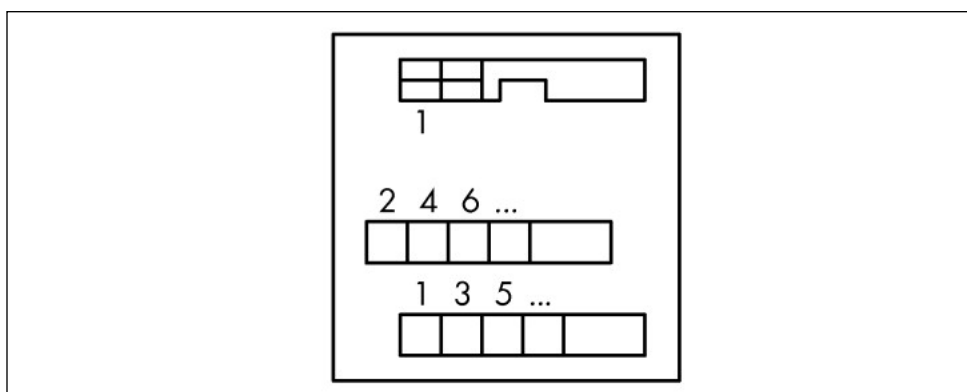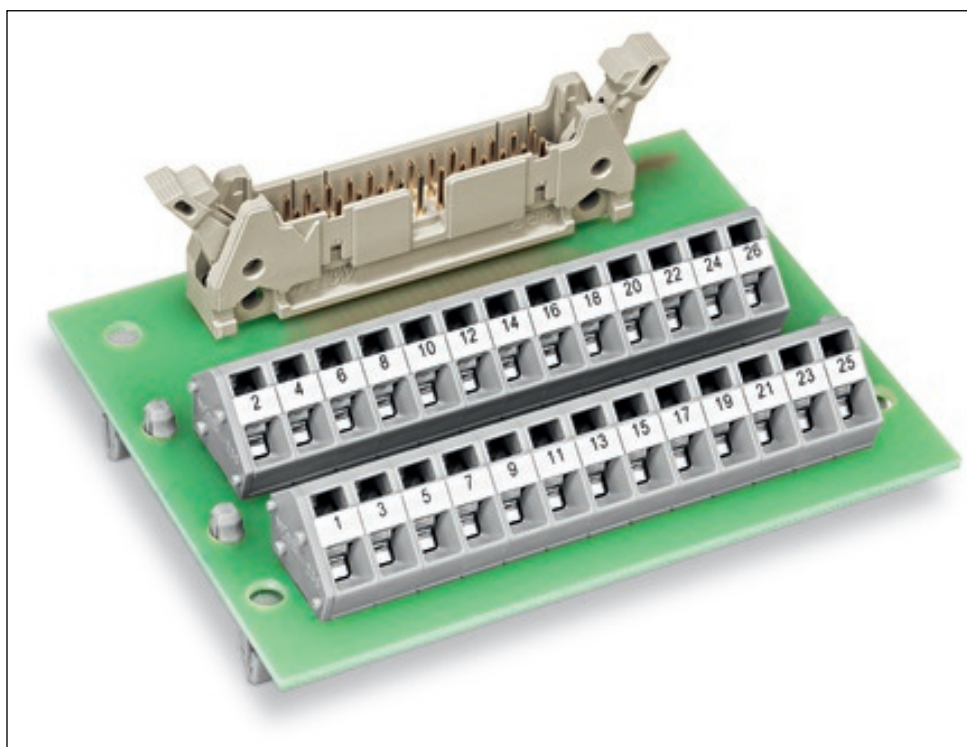

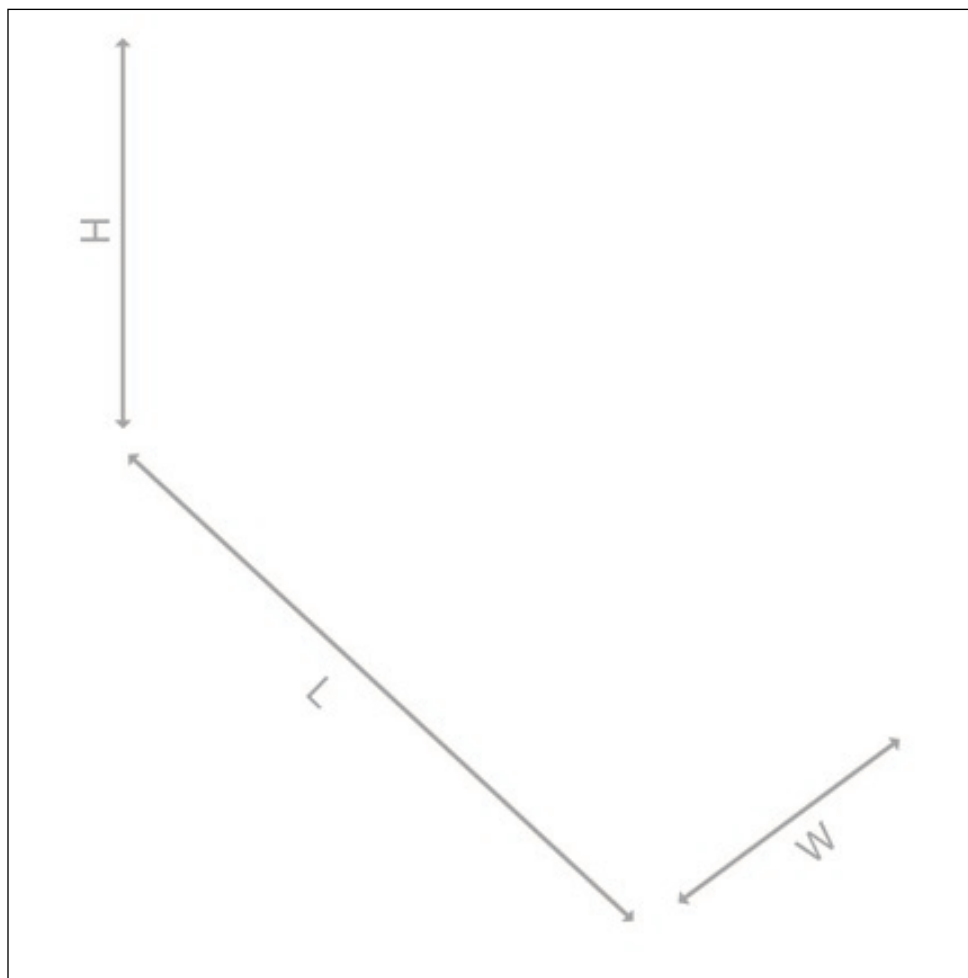

#### Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.