



**Interface module; with male connector; 64-pole; for female header with solder contact; Type C; for connectors per DIN 41612; Horizontal mounting**

*Item No.: 289-527*



---

*Interface module; with male connector; 64-pole; for female header with solder contact; Type C; for connectors per DIN 41612; Horizontal mounting*

## Marking

RoHS ✓  
Compliant

## Business data

|                   |               |
|-------------------|---------------|
| <i>Supplier</i>   | WAGO          |
| <i>Item no.</i>   | 289-527       |
| <i>GTIN / EAN</i> | 4045454594190 |
| <i>Content</i>    | 1             |
|                   |               |
|                   |               |

## Notes

## Technical data



### Miscellaneous


|                              |                     |
|------------------------------|---------------------|
|                              |                     |
| <i>No. of poles</i>          | 64                  |
| <i>Connection type (1)</i>   | Connectors          |
| <i>Connection technology</i> | Connectors          |
| <i>Connection type (2)</i>   | PCB terminal blocks |

Printview: Interface module; with male connector; 64-pole; for female header with solder contact; Type C; for connectors per DIN 41612; Horizontal mounting - Item No.: 289-527

| Technical data                        |                                                       |
|---------------------------------------|-------------------------------------------------------|
| Connection technology 2               | CAGE CLAMP®                                           |
| Solid conductor (2)                   | 0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG          |
| Fine-stranded conductor (2)           | 0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG          |
| Strip length (2)                      | 5 ... 6 mm / 0.2 ... 0.24 Inch                        |
| Wire connection 2                     | WAGO 236 Series                                       |
| Width                                 | 171 mm / 6.732 Inch                                   |
| Height from upper-edge of DIN-35 rail | 34 mm / 1.339 Inch                                    |
| Depth                                 | 85 mm / 3.346 Inch                                    |
| Type of mounting                      | DIN-35 rail                                           |
| Connector contact                     | Copper alloy, gold plated                             |
| Fire load [MJ]                        | 2.527 [MJ]                                            |
| Weight [g]                            | 174.5 [g]                                             |
| Pollution degree                      | 2                                                     |
| Housing design                        | Mounting carrier                                      |
| Main product function                 | Interface module for pluggable connectors (DIN 41612) |
| Product type                          | Universal module                                      |

## Images & drawings

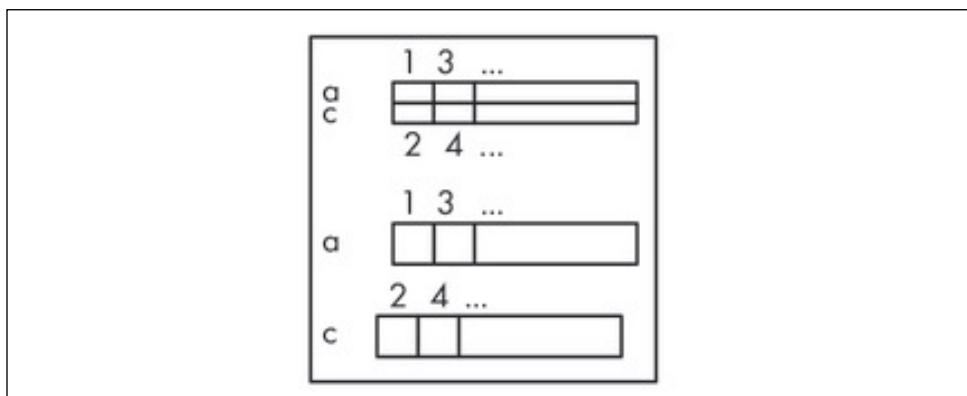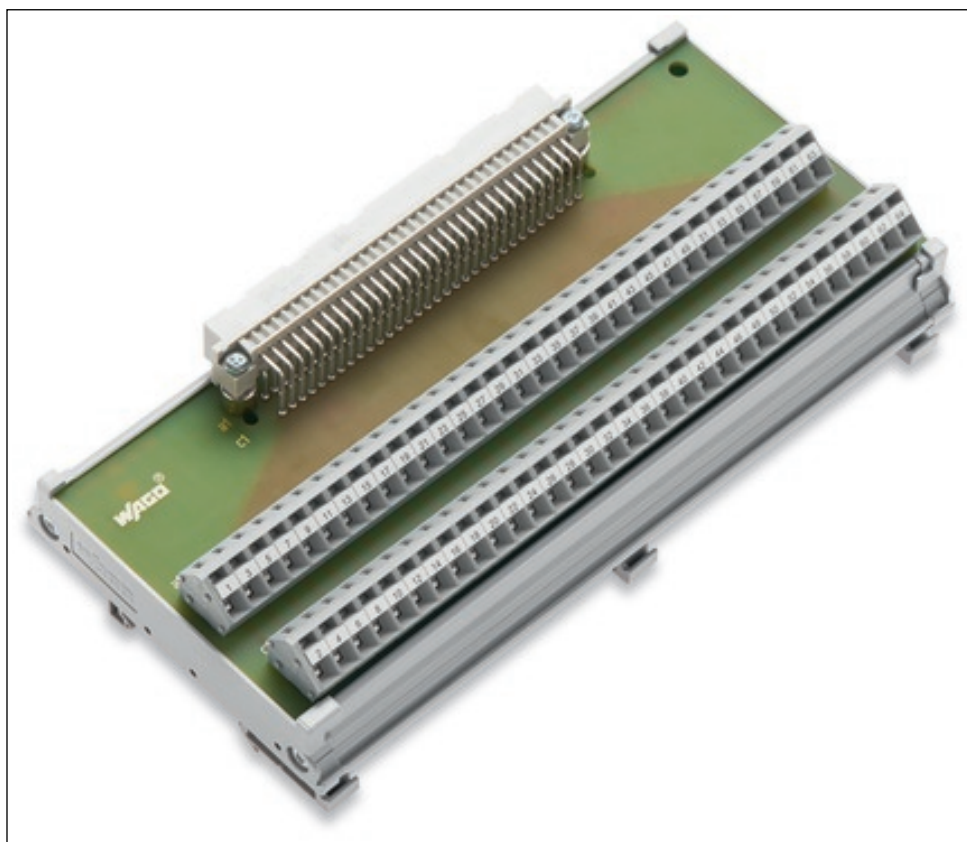

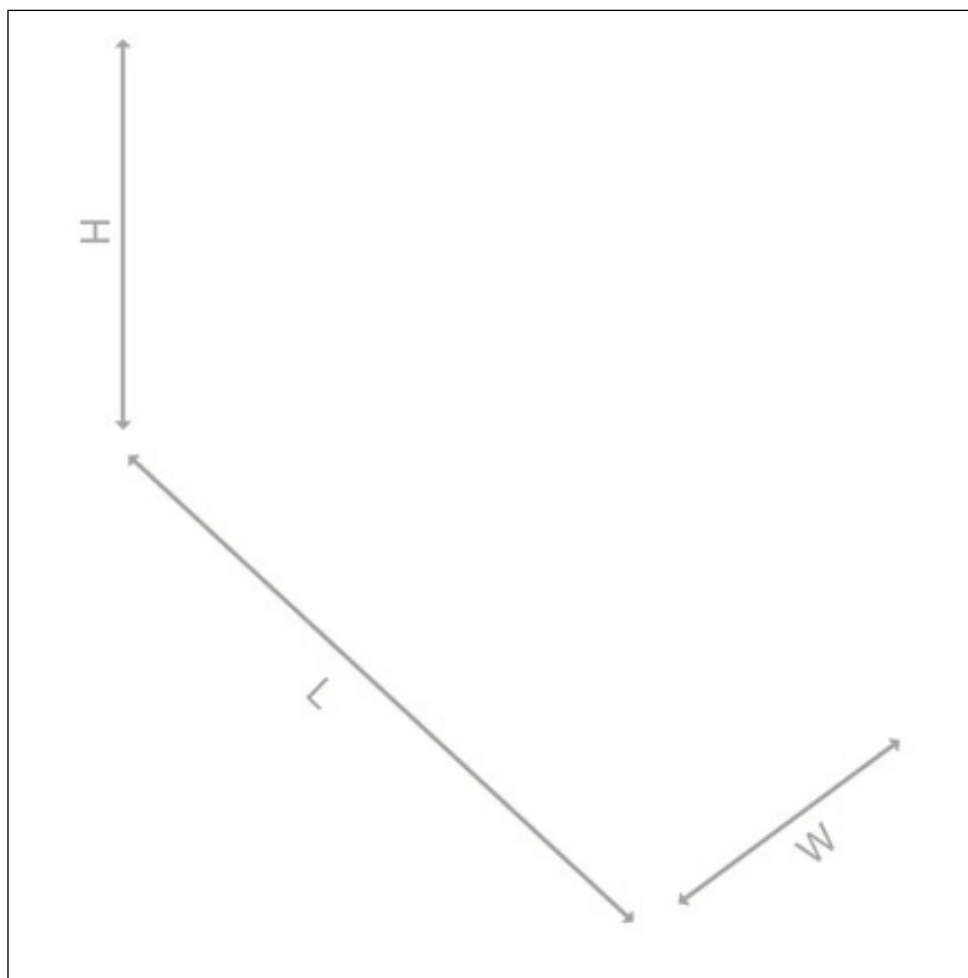

#### Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.