



Interface module; with D-subminiature male connector; 25-pole;
for mating connectors with IDC; Vertical mounting

Item No.: 289-542



Interface module; with D-subminiature male connector; 25-pole; for mating connectors with IDC; Vertical mounting

Marking

RoHS ✓
Compliant


Business data	
Supplier	WAGO
Item no.	289-542
GTIN / EAN	4045454362096
Content	1


Notes


Technical data	
Miscellaneous	
No. of poles	25
Connection type (1)	Connectors
Connection technology	Connectors
Connection type (2)	PCB terminal blocks
Connection technology 2	CAGE CLAMP®

Technical data	
<i>Solid conductor (2)</i>	<i>0.08 ... 2.5 mm² / 28 ... 12 AWG</i>
<i>Fine-stranded conductor (2)</i>	<i>0.08 ... 2.5 mm² / 28 ... 12 AWG</i>
<i>Strip length (2)</i>	<i>5 ... 6 mm / 0.2 ... 0.24 Inch</i>
<i>Wire connection 2</i>	<i>WAGO 236 Series</i>
<i>Pull relief stud bolt</i>	<i>UNC 4-40</i>
<i>Width</i>	<i>72 mm / 2.835 Inch</i>
<i>Height from upper-edge of DIN-35 rail</i>	<i>34 mm / 1.339 Inch</i>
<i>Depth</i>	<i>85 mm / 3.346 Inch</i>
<i>Type of mounting</i>	<i>DIN-35 rail</i>
<i>Degree of protection</i>	<i>IP20</i>
<i>Connector contact</i>	<i>Au over Ni</i>
<i>Fire load [MJ]</i>	<i>1.2 [MJ]</i>
<i>Weight [g]</i>	<i>82.2 [g]</i>
<i>Ambient temperature (operation)</i>	<i>-20 ... 50 °C</i>
<i>Ambient temperature (storage)</i>	<i>-40 ... 70 °C</i>
<i>Relative humidity</i>	<i>max. 85 % (nicht betauend)</i>
<i>Pollution degree</i>	<i>2</i>
<i>Standards/specifications</i>	<i>UL 840</i>
<i>Housing design</i>	<i>Mounting carrier</i>
<i>Main product function</i>	<i>Interface module with Sub-D/Sub-H-D contact</i>
<i>Product type</i>	<i>Universal module</i>

Images & drawings

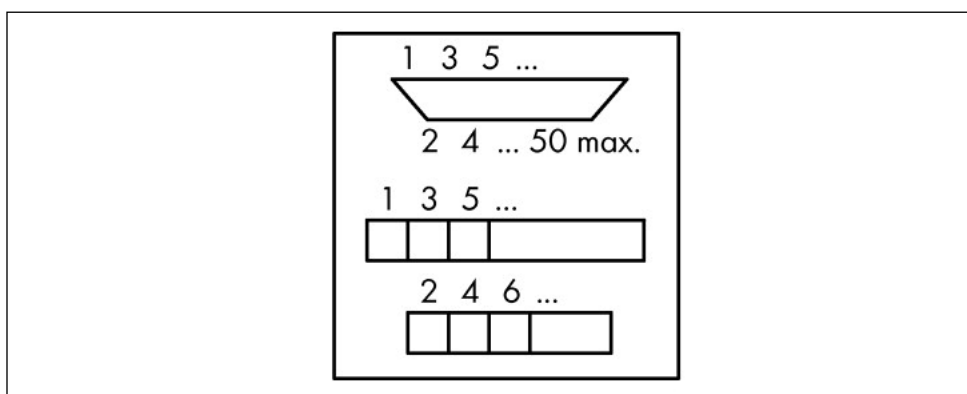

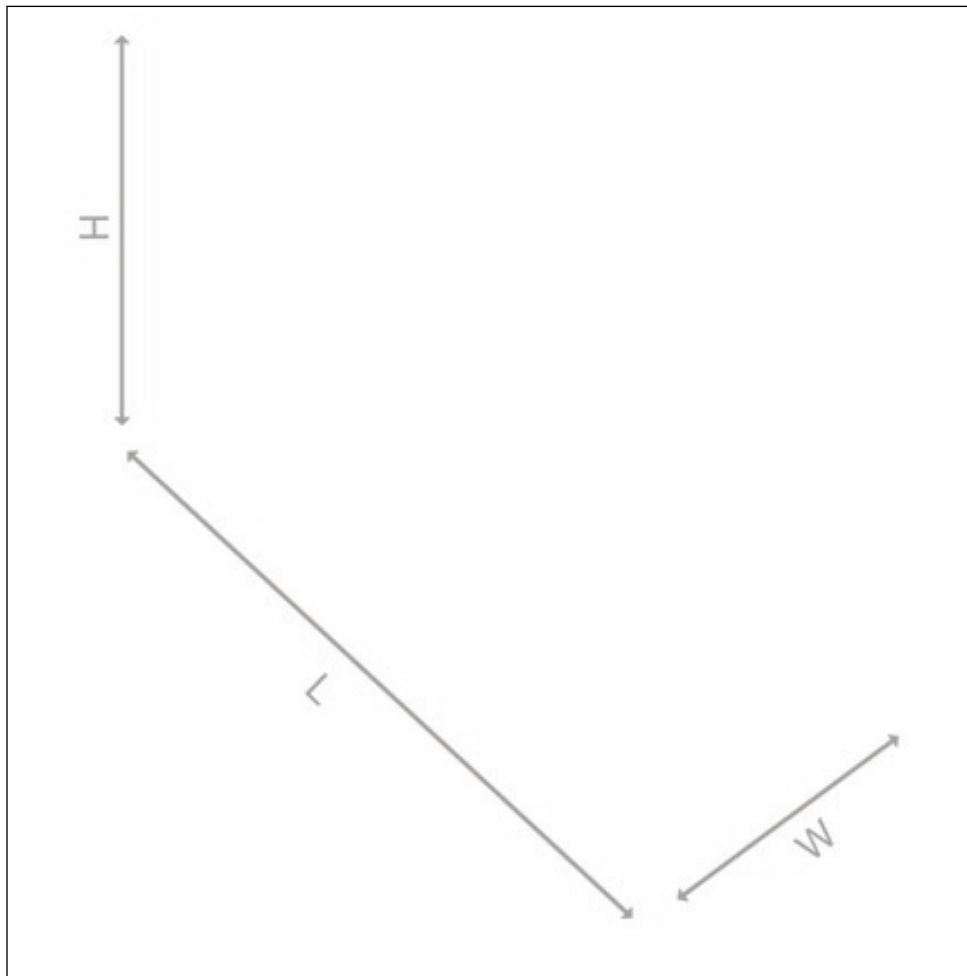

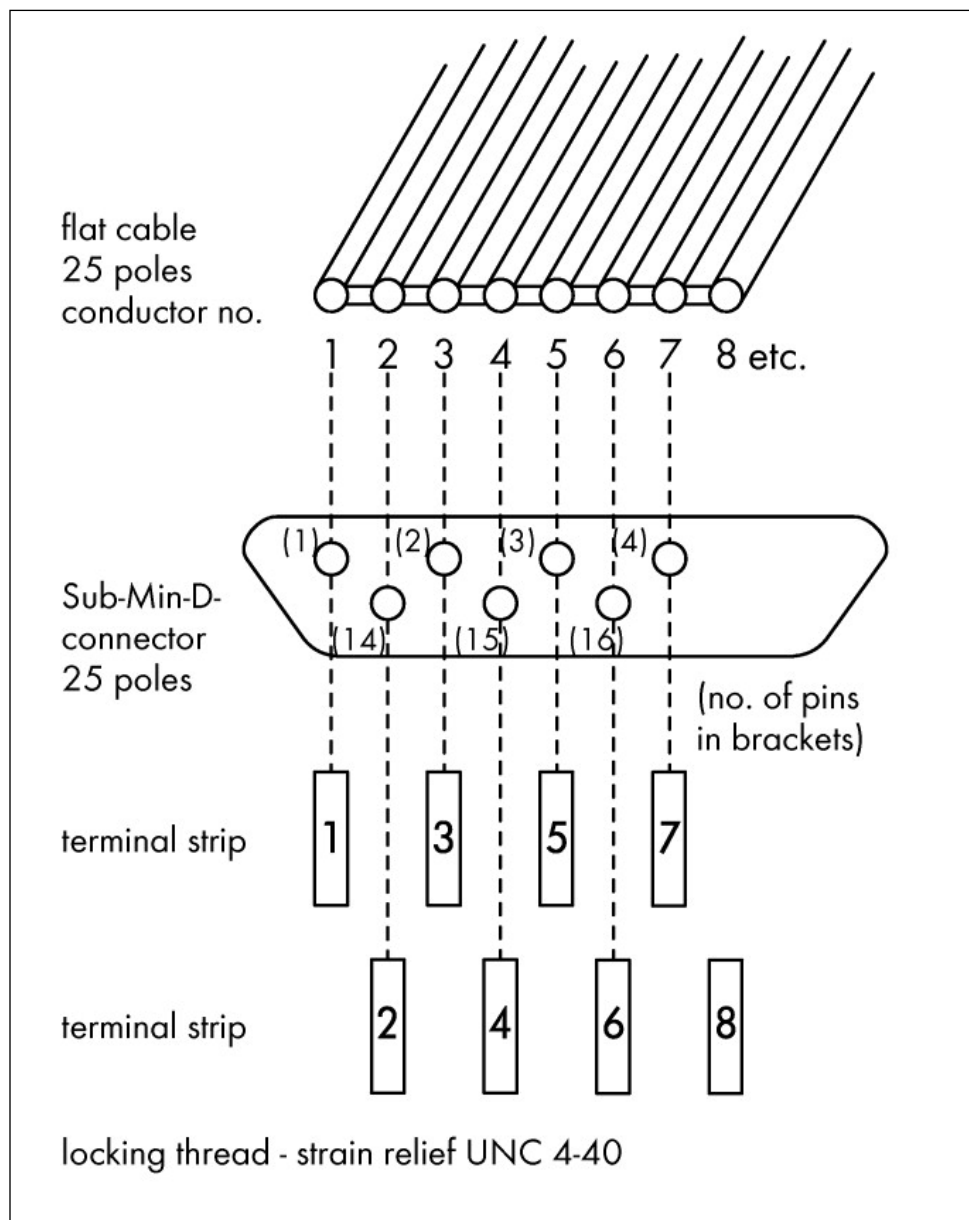

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.