


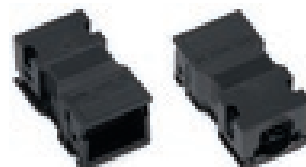

Strain relief housing; 2-pole; Cable diameter 5 - 9 mm; for 1 cable

Item No.: 770-502/042-000



Strain relief housing; 2-pole; Cable diameter 5 - 9 mm; for 1 cable

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	770-502/042-000
GTIN / EAN	4050821137566
Content	1

Notes

Note on Continuous Service Temperature:-35°C to +85°CInsulating parts for temperatures 105°C


Technical data


Miscellaneous

No. of poles	2
Connectable sheathed cable diameter	5 ... 9 mm
Width	24.6 mm / 0.969 Inch
Height	15.9 mm / 0.626 Inch
Depth	45 mm / 1.772 Inch

Technical data	
Degree of protection	IP20
Color	black
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0
Fire load [MJ]	0.195 [MJ]
Weight [g]	6.57 [g]
Ambient temperature (operation)	-35 ... 85 °C
Processing temperature	-5°C ... +40°C
Product Family	WINSTA MIDI
Main product function	Strain relief housing
Product type	Accessories

Images & drawings

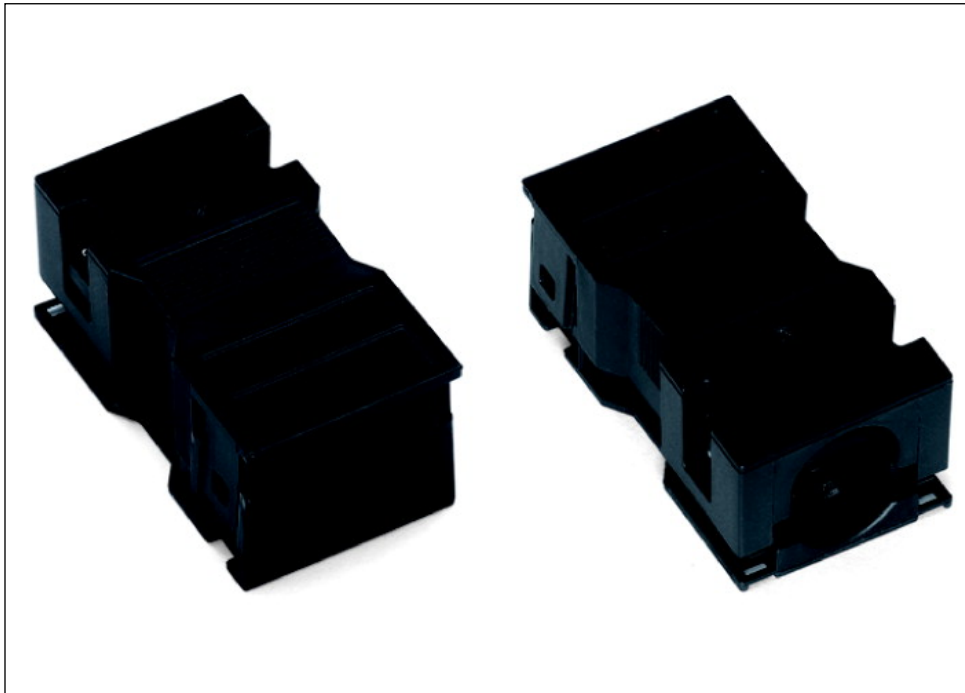

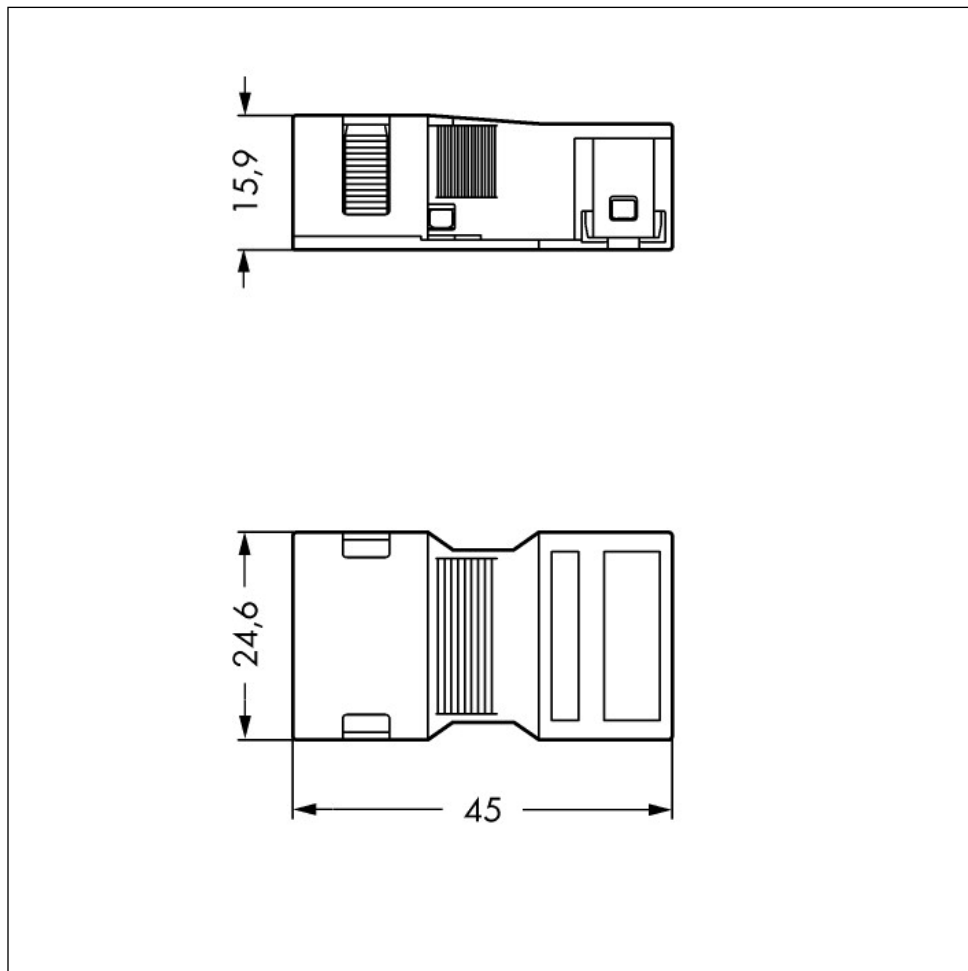

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.