

Printview: Terminal strip (compact block terminal strip); with snap-in mounting feet; for plate thickness 0.6 - 1.2 mm; Fixing hole 3.5 + 0.1 mm Ø; 4-pole - Item No.: 869-154



**Terminal strip (compact block terminal strip); with snap-in mounting feet; for plate thickness 0.6 - 1.2 mm; Fixing hole 3.5 + 0.1 mm Ø; 4-pole**

Item No.: 869-154



Terminal strip (compact block terminal strip); with snap-in mounting feet; for plate thickness 0.6 - 1.2 mm; Fixing hole 3.5 + 0.1 mm Ø; 4-pole

## Marking

RoHS ✓  
Compliant

## Business data

Supplier	WAGO
Item no.	869-154
GTIN / EAN	4044918481151
Content	1

## Notes

## Technical data

### Miscellaneous

Safety information 1	Max. insulation diameter: 4.4mm
Rated voltage (III / 3) [V]	500 [V]
Rated impulse voltage (III / 3) [kV]	6 [kV]
Rated current [A]	24 [A]


Printview: Terminal strip (compact block terminal strip); with snap-in mounting feet; for plate thickness 0.6 - 1.2 mm; Fixing hole 3.5 + 0.1 mm Ø; 4-pole - Item No.: 869-154

<b>Technical data</b>	
<i>Legend (ratings)</i>	<i>(III / 3) Overvoltage category III / Pollution degree 3</i>
<i>Type of wiring</i>	<i>Front-entry wiring</i>
<i>No. of poles</i>	<i>4</i>
<i>Total number of connection points</i>	<i>8</i>
<i>Total number of potentials</i>	<i>4</i>
<i>Number of levels</i>	<i>1</i>
<i>Connection technology</i>	<i>CAGE CLAMP®</i>
<i>Actuation type</i>	<i>Operating tool</i>
<i>Connectable conductor materials</i>	<i>Copper</i>
<i>Solid conductor</i>	<i>0.08 ... 2.5 mm<sup>2</sup> / 28 ... 12 AWG</i>
<i>Fine-stranded conductor</i>	<i>0.08 ... 4 mm<sup>2</sup> / 28 ... 12 AWG</i>
<i>Strip length</i>	<i>6 ... 7 mm / 0.24 ... 0.28 Inch</i>
<i>Width</i>	<i>22.5 mm / 0.886 Inch</i>
<i>Height from the surface</i>	<i>27.6 mm / 1.087 Inch</i>
<i>Depth</i>	<i>33.4 mm / 1.315 Inch</i>
<i>Design</i>	<i>horizontal</i>
<i>Mounting type</i>	<i>Snap-in mounting foot</i>
<i>Marking level</i>	<i>Side marking</i>
<i>Color</i>	<i>gray</i>
<i>Fire load [MJ]</i>	<i>0.336 [MJ]</i>
<i>Weight [g]</i>	<i>17.864 [g]</i>
<i>Main product function</i>	<i>Through term. block</i>
<i>Product type</i>	<i>Miniature rail-mount terminal blocks</i>

Printview: Terminal strip (compact block terminal strip); with snap-in mounting feet; for plate thickness 0.6 - 1.2 mm; Fixing hole 3.5 + 0.1 mm Ø; 4-pole - Item No.: 869-154

---

## Images & drawings

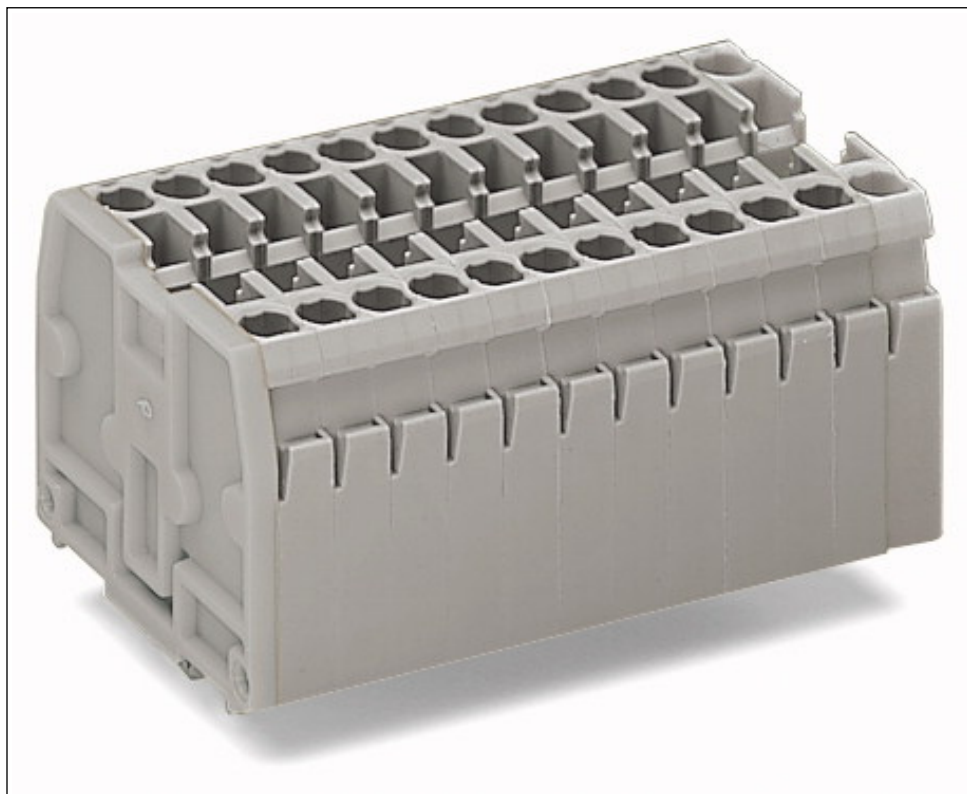

## Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.