


NM-D900BLACK

Neomounts by Newstar Select Full Motion Desk Mount (clamp & grommet) for 10-30" Monitor Screen, Height Adjustable (gas spring) - Black

NEOMOUNTS BY NEWSTAR SELECT MONITOR

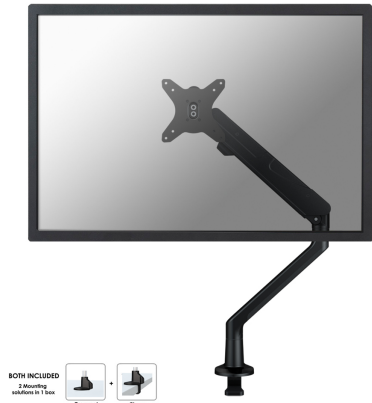

SPECIFICATIONS

Color	Black
Depth	0-54 cm
Desk mount	Grommet Clamp
Height	14-49 cm
Height adjustment	Gaspring
Max. screen size	30
Max. weight	10
Min. screen size	10
Min. weight	0
Rotate (degrees)	360°
Screens	1
Swivel (degrees)	360°
Tilt (degrees)	360°
Type	Tilt Rotate Swivel Full motion
VESA maximum	100x100 mm
VESA minimum	75x75 mm
VESA pattern	75x75 100x100
Warranty	5 year
EAN code	8717371445461

The Neomounts Select desk mount, model NM-D900BLACK is a tilt-, swivel and rotatable desk mount for flat screens up to 30". This mount is a great choice for space saving placement on desks using a desk clamp or grommet mount.

Neomounts Select's versatile tilt (180°), rotate (360°) and swivel (360°) technology allows the mount to change to any viewing angle to fully benefit from the capabilities of the flat screen. The mount is easily height adjustable from 14 to 49 centimetres using a gas spring. Depth adjustable from 0 to 54 centimetres. An innovative cable management conceals and routes cables from mount to flat screen. Hide your cables to keep the workplace nice and tidy.

Neomounts Select NM-D900BLACK has three pivot points and is suitable for screens up to 30" (76 cm). The weight capacity of this product is 10 kg each screen. The desk mount is suitable for screens that meet VESA hole pattern 75x75 or 100x100mm. Different hole patterns can be covered using Neomounts Select VESA adapter plates.

By using an ergonomic mount neck- and back complaints can be avoided. Ideal for use in offices and on counters or in a reception area.

All installation material is included with the product.

NM-D900BLACK

NEOMOUNTS BY NEWSTAR SELECT MONITOR

