

NMPRO-WMB4

NEOMOUNTS PRO MENU BOARD WALL MOUNT

SPECIFICATIONS

GENERAL

Min. screen size*	32 inch
Max. screen size*	55 inch
Min. weight	0 kg (per screen)
Max. weight	30 kg (per screen)
Screens	4
VESA minimum	100x100 mm
VESA maximum	600x400 mm

FUNCTIONALITY

Type	Tilt Fixed
Height adjustment	44 cm
Width adjustment	449 cm
Depth adjustment	6 cm
Tilt (degrees)	21°
Adjustment type	Micro adjustment

INFORMATION

Color	Black
Main material	Aluminium
Warranty	5 year
EAN code	8717371447564

*Please note: The inch sizes stated are just an indication, combined with the weight and VESA sizes. The maximum weight and VESA size are absolute restrictions for the products and should not be exceeded.



Neomounts



Neomounts

Neomounts Pro Menuboard Wall mount for four 32"-55"/65" Screens - Black


The Neomounts Pro menuboard wall mount, model NMPRO-WMB4, is a tiltable wall mount for four flat screens up to 55"/65". This mount is a great choice when you want the ultimate viewing flexibility with your flat screen. The Neomounts Pro tilt (0°/-6°/+15°) technology allows the mount to change to the best suitable viewing angle.

Neomounts Pro NMPRO WMB-series is suitable for 1 to 4 screens. The weight capacity of this product is 30 kg each screen. The wall mount is suitable for screens that meet VESA 100x100 to 400x400mm (65") or VESA 100x100 to 600x400mm (55"). Depth of this mount is 5,6 centimetres.

* All installation material is included with the product.

NMPRO-WMB4

NEOMOUNTS PRO MENU BOARD WALL MOUNT

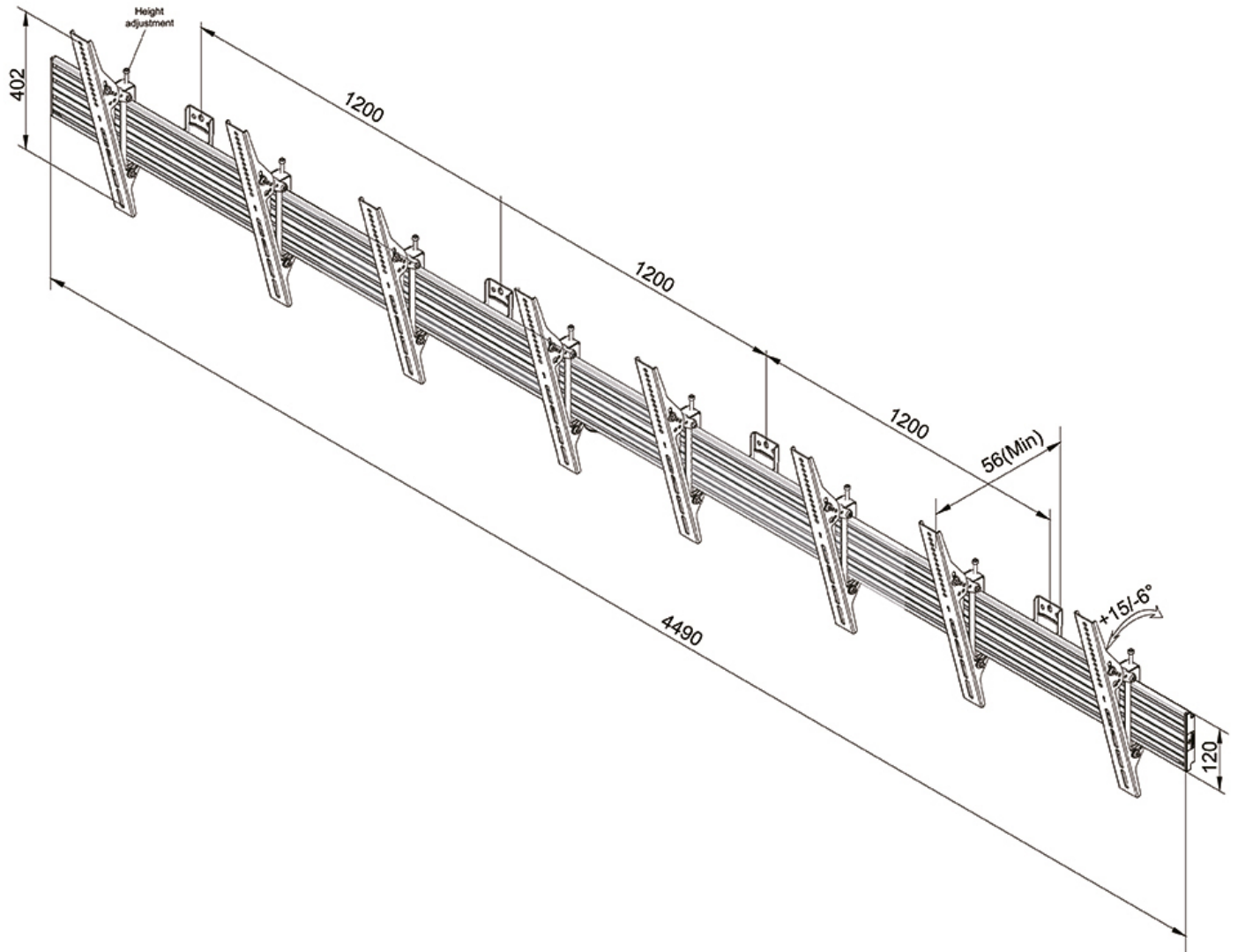

Neomounts

Measuring unit: mm