

NS-WMB300BLACK

NEOMOUNTS MENU BOARD WALL MOUNT

SPECIFICATIONS

GENERAL

Min. screen size*	40 inch
Max. screen size*	52 inch
Min. weight	0 kg (per screen)
Max. weight	50 kg (per screen)
Screens	3
VESA minimum	200x200 mm
VESA maximum	600x400 mm
Distance to wall	7,6 cm

FUNCTIONALITY

Type	Tilt
Height adjustment	48 cm
Width adjustment	29 cm
Tilt (degrees)	20°
Rotate (degrees)	6°
Adjustment type	Micro adjustment

INFORMATION

Color	Black
Main material	Steel
Warranty	5 year
EAN code	8717371447359

*Please note: The inch sizes stated are just an indication, combined with the weight and VESA sizes. The maximum weight and VESA size are absolute restrictions for the products and should not be exceeded.



Neomounts



Neomounts

Neomounts Menu Board Wall Mount for 40"-52" Screen - Black


The Neomounts menu board wall mount, model NS-WMB300BLACK is a tiltable wall mount for three flat screens up to 52" (132 cm). This mount is a great choice when you want the ultimate viewing flexibility with your flat screen. Neomounts tilt (0°/-5°/-10°/-15°/-20°) technology allows the mount to change to any viewing angle to fully benefit from the capabilities of the flat screen. Depth of this mount is 7,6 centimetres.

Neomounts NS-WMB300BLACK is suitable for 3 screens up to 52" (132 cm). The weight capacity of this product is 50 kg each screen. The wall mount is suitable for screens that meet VESA hole pattern 200x200 to 600x400 mm.

All installation material is included with the product.

NS-WMB300BLACK

NEOMOUNTS MENU BOARD WALL MOUNT

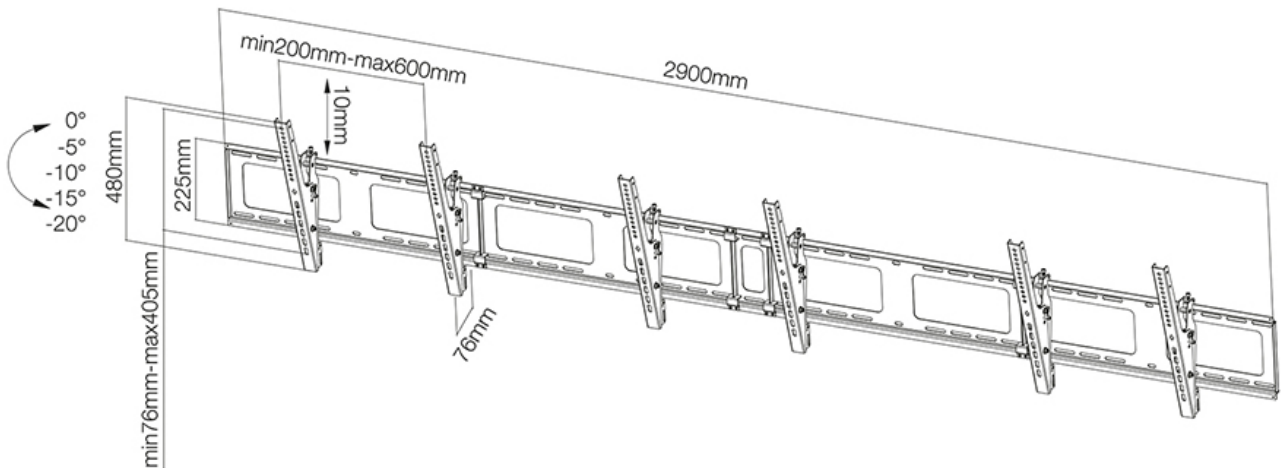

Neomounts