

2.54mm PCB connectors

Order code	Manufacturer code	Description
22-0975	n/a	8 WAY STRAIGHT HEADER (RC)
22-0985	n/a	10 WAY STRAIGHT HEADER (RC)
22-0960	n/a	4 WAY STRAIGHT HEADER (RC)
22-0965	n/a	5 WAY STRAIGHT HEADER (RC)
22-0970	n/a	6 WAY STRAIGHT HEADER (RC)
22-2405	n/a	15 WAY STRAIGHT PIN HEADER (RC)
22-0950	n/a	2 WAY STRAIGHT HEADER (RC)
22-0955	n/a	3 WAY STRAIGHT HEADER (RC)
22-2390	n/a	7 WAY STRAIGHT PIN HEADER (RC)
22-2395	n/a	9 WAY STRAIGHT PIN HEADER (RC)
22-2400	n/a	12 WAY STRAIGHT PIN HEADER (RC)

2.54mm PCB connectors	Page 1 of 2
The enclosed information is believed to be correct, Information may change 'without notice' due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E.	Revision A 04/07/2003


0.1 STRAIGHT HEADER

Material:



Post: Brass

Insulator: Nylon 6/6 UL 94V-2

Plating: Tin Plated

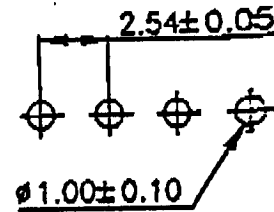

Recommended P.C.B. hole layout

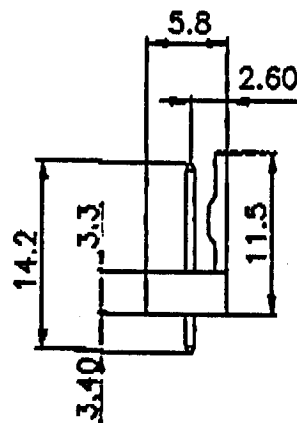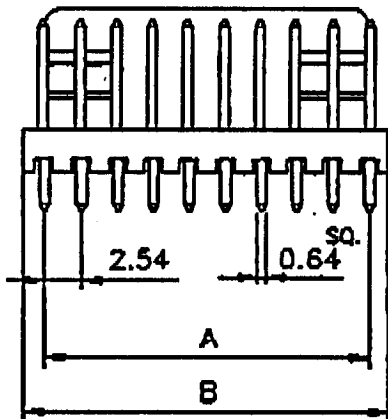

SPECIFICATION

VOLTAGE RATING : AC, DC, 250V max

CURRENT RATING : 3A. max

APPLICABLE PC BOARD THICKNESS : .063" (1.6mm)

Circuits	Dim A	Dim B
2	2.54	5.1
3	5.08	7.6
4	7.62	10.2
5	10.16	12.7
6	12.70	15.2
7	15.24	17.8
8	17.78	20.3
9	20.32	22.9
10	22.86	25.4
12	27.94	30.5
15	35.56	38.1