


2.54mm PCB connectors

Order code	Manufacturer code	Description
22-1005	n/a	2 WAY RIGHT ANGLE HEADER (RC)
22-1010	n/a	3 WAY RIGHT ANGLE HEADER (RC)
22-1025	n/a	6 WAY RIGHT ANGLE HEADER (RC)
22-1030	n/a	8 WAY RIGHT ANGLE HEADER (RC)
22-1040	n/a	10 WAY 0.1 RIGHT ANGLE HEADER (RC)
22-2435	n/a	15 WAY 90 DEGREE PIN HEADER
22-1015	n/a	4 WAY RIGHT ANGLE HEADER (RC)
22-1020	n/a	5 WAY RIGHT ANGLE HEADER (RC)
22-2420	n/a	7 WAY 90 DEGREE PIN HEADER (RC)
22-2425	n/a	9 WAY 90 DEGREE PIN HEADER (RC)
22-2430	n/a	12 WAY 90 DEGREE PIN HEADER (RC)

2.54mm PCB connectors	Page 1 of 2
The enclosed information is believed to be correct, Information may change without notice due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E.	Revision A 20/02/2007

Connectors – Multipole

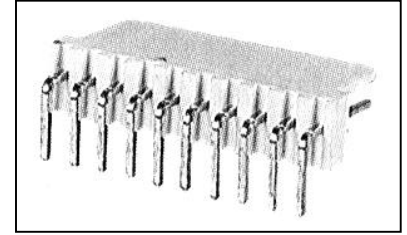

90° Pin Header with Friction Lock


Materials:

Post: Brass
Insulator: Nylon 6/6 UL 94V-2
Plating: Tin Plated

Specification:

Voltage Rating: AC/DC 250V max.
Current rating: 3A max.
Applicable PC board thickness: 0.63" (1.6mm)

Dimensions (mm):

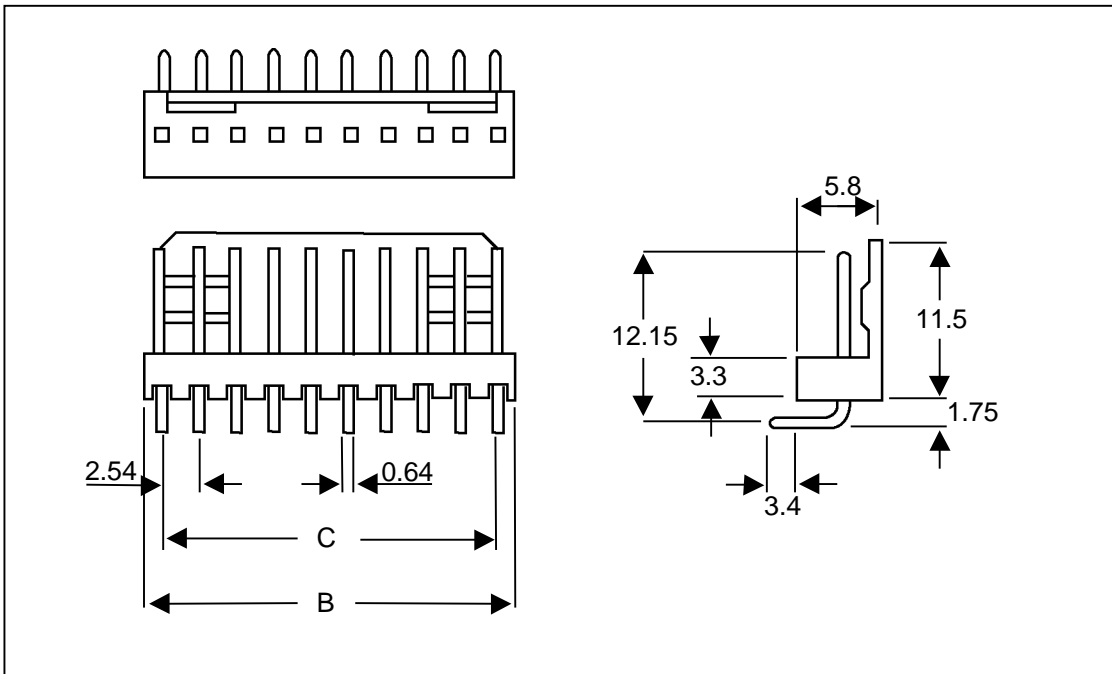

No of Ways	Dimension A	Dimension B
2	2.54	5.1
3	5.08	7.6
4	7.62	10.2
5	10.16	12.7
6	12.70	15.2
7	15.24	17.8
8	17.78	20.3
9	20.23	22.9
10	22.86	25.4
12	27.94	30.5
15	35.56	38.1