


3.00mm Pitch housing-receptacle, micro-fit

Order code: **22-3600**



 






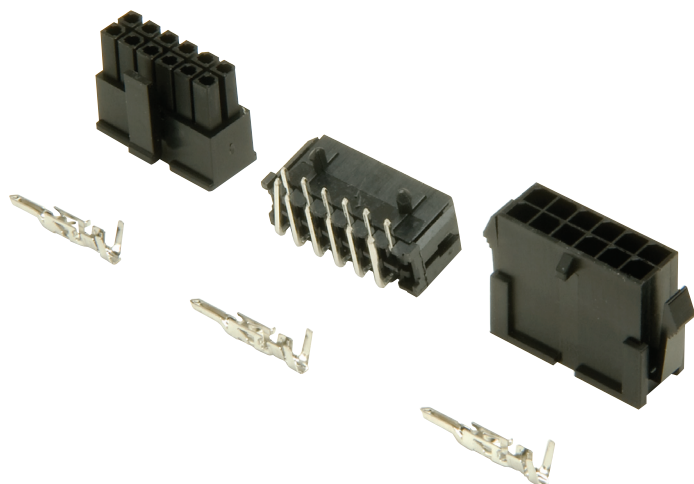


Ordering information & dimensions:

Specifications:

Current rating	5A AC, DC
Voltage rating	250V AC, DC
Temperature range	-25° to +85°C
Contact resistance	10mΩ max.
Insulation resistance	100MΩ min.
Withstanding voltage	1500V AC/minute
Material	Nylon 66.UL94V-2
Colour	Black

No. of pins	Dimensions	
	A	B
2 x 1	–	3.80
2 x 2	3.00	6.80
2 x 3	6.00	9.80
2 x 4	9.00	12.80
2 x 5	12.00	15.80
2 x 6	15.00	18.80
2 x 7	18.00	21.80
2 x 8	21.00	24.80
2 x 9	24.00	27.80
2 x 10	27.00	30.80
2 x 11	30.00	33.80
2 x 12	33.00	36.80

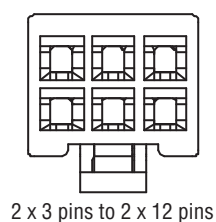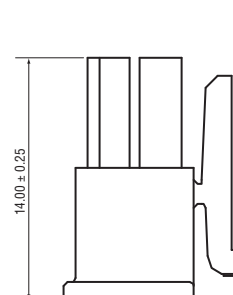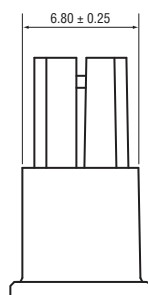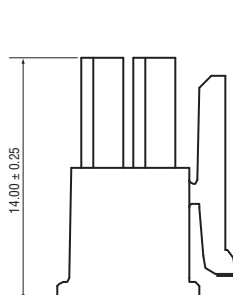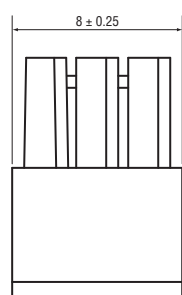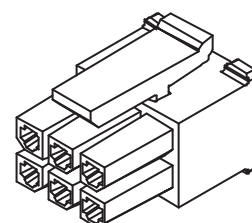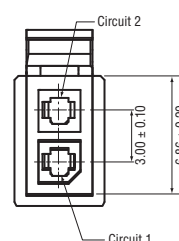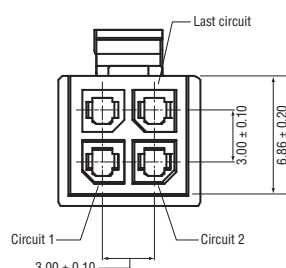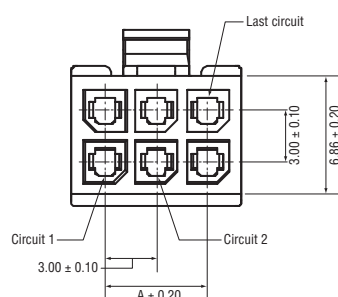

2 x 3 pins to 2 x 12 pins