
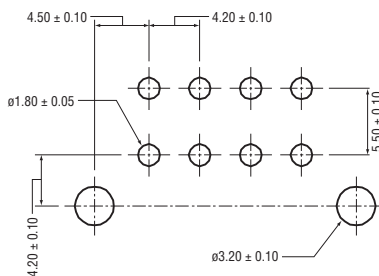


Ordering information & dimensions:

No. of pins	Dimensions	
	A	B
2 x 1	-	5.40
2 x 2	4.20	9.60
2 x 3	8.40	13.80
2 x 4	12.60	18.00
2 x 5	16.80	22.20
2 x 6	21.00	26.40
2 x 7	25.20	30.60
2 x 8	29.40	34.80
2 x 9	33.60	39.00
2 x 10	37.80	43.20
2 x 11	42.00	47.40
2 x 12	46.20	51.60

Specifications:

Current rating	9A AC, DC
Voltage rating	600V AC, DC
Temperature range	-25° to +85°C
Contact resistance	10mΩ max.
Insulation resistance	100MΩ min.
Withstanding voltage	1500V AC/minute
Pin material	Brass/Tin-plated
Material	Nylon 66.UL94V-2
Colour	Natural (Translucent)

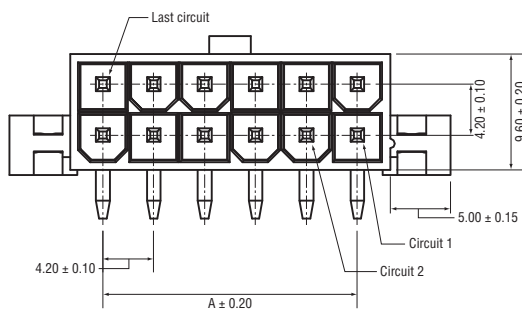

P.C.B. LAYOUT

