


Product Code: PA195015BK

Description: C19 IEC Locking Appliance Outlet - Black

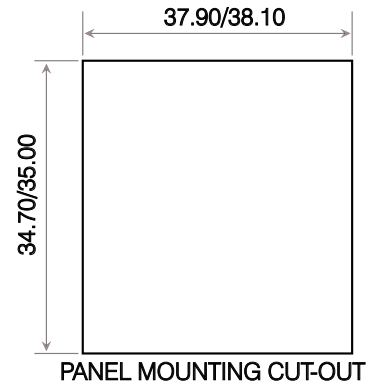

General Information

Rating	16A Max / 250V~ (Europe) 16A Max / 250V~ (cUL)
Materials	Outer Body & Chassis: Nylon (PA66) LSZH (RAL 9004 Signal Black) Cable Restraint: Nylon (PA66) Housing Screws & Cable Restraint Screws: Steel, Nickel Plated Lock Pivot Lever: Polycarbonate Terminal Block & Sliding Terminal: Brass Terminal Screws: Steel, Yellow Passivated Spring: Spring Steel Locking Blade: Spring Steel Zinc Plated Red Handle: Polycarbonate LSZH (RAL 3020 Traffic Light Red)
Panel Thickness	1.5mm
Aperture Cutout	(37.9-38.1mm) x (34.7-35.0mm)
Receptacle Size	6.3mm x 0.8mm
Insulation Resistance	100MΩ (500V DC, 1 Min)
Dielectric Strength	2KV (50Hz 1Min) to accessible surfaces
Temperature Rating	-20°C To + 70°C
Lock Retention	> 100N
Features	Fits any standard C20 connector Anti-Vibrate Integral plug retention feature Easy push button to release

Standards	IEC / EN 60320-1:2015 (DEKRA File NL-45977) UL 498 (UL File E348985) C22.2 No. 182.3-M1987 (UL File E348985)
------------------	--

