

IEC connectors

Order code	Manufacturer code	Description
23-0362	PX0714/2/15/28	2 WAY PUSH FIT IEC OUTLET
23-0364	PX0714/4/15/28	4 WAY PUSH FIT IEC OUTLET

IEC connectors	Page 1 of 3
The enclosed information is believed to be correct, Information may change 'without notice' due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E.	Revision A 04/07/2003

Multiple Push Fit IEC Sockets


Bulgin – 2 & 4 Way IEC Outlets

Prewired push fit two and four way IEC socket outlets fitted with solid busbars and solder tags. Single piece moulding

Technical Specifications

Outlet Ratings:	15A, 250V (UL & CSA) 10A, 250V (VDE, SEMKO & SEV)
Terminations:	2.8mm solder
Fixing (panel):	Snap-to-panel – 1.5mm
Interconnections:	Solid busbars
Temperature:	65°C
Materials:	
Mouldings:	Polymide 66 (dupont "Zytel" Fr10) UL94 V-O rated
Contacts:	Plated copper alloy
Busbars:	Plated copper alloy

Approvals: UL, CSA, SEMKO, NEMKO, SETI, SEV & VDE Pending

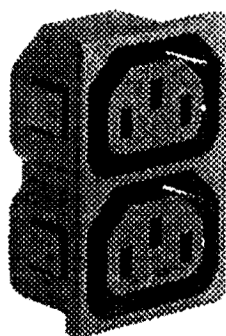

Bulgin Code	Description
PX0714/2/15/28	2 Way IEC Push Fit Outlet
PX0714/4/15/28	4 Way IEC Push Fit Outlet

