


Data Sheet

IEC C19 Socket



Drawing:

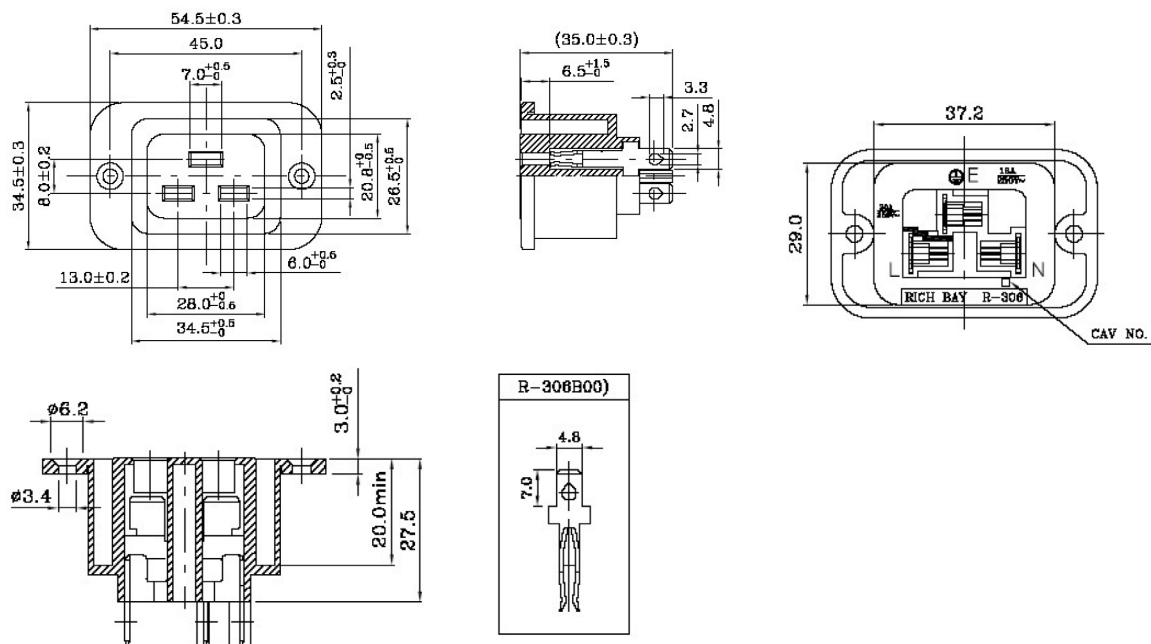

Technical data

Color: Black

Appliance plug standard: C19

Total number of poles: 2 + PE

Rating: 16 A, 250 V AC

Insulation resistance: Over 100 MΩ 600 V DC

Dielectric strength: 2000 V AC 1 min.

Body material: Black glass-fiber thermoplastic, UL 94V-2~0