


Order code	Manufacturer code	Description
23-1000	332-407	SD7 JUNCTION BOX WITH TERMINAL
23-1002	332-907	SD7 JUNCTION BOX NO TERMINALS
23-1004	332-412	I12 JUNCTION BOX WITH TERMINAL
23-1006	332-912	I12 JUNCTION BOX NO TERMINALS

	Page 1 of 2
The enclosed information is believed to be correct, Information may change 'without notice' due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E.	Revision A 04/07/2003

Thermoplastic Junction Boxes

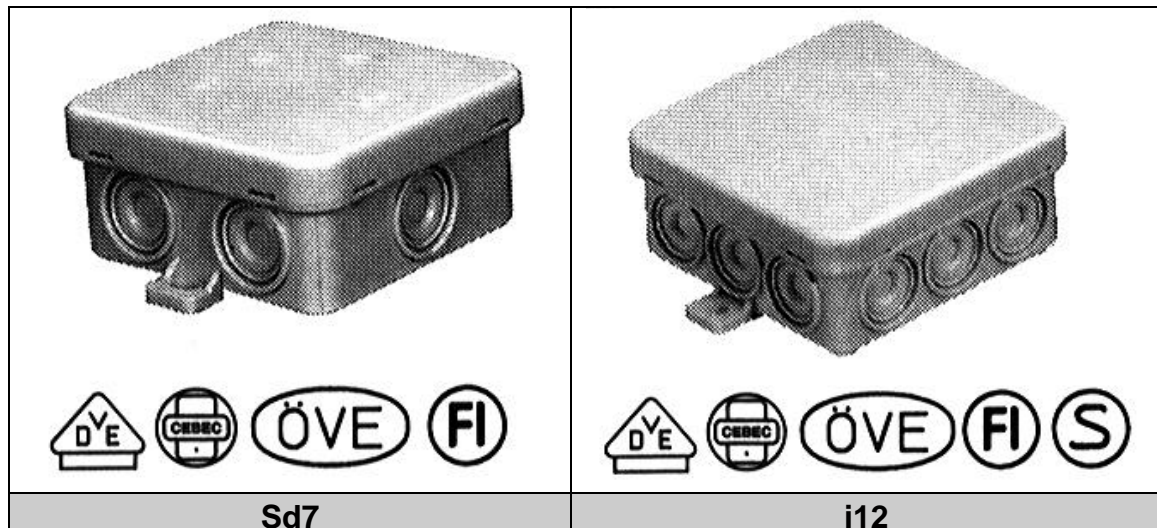

Moulded in light grey frame resistant thermoplastic, with snap-fit lids.
Boxes maybe surface mounted, either inside the box or externally on fixing lugs.
VDE, CEBC, OVE, FEMKO approved. Larger boxes also have SEMKO approval.

Case material	:	Heat resistant thermoplastic
Case colour	:	Grey
IP rating	:	IP54
Heat resistant	:	upto 100°C
Terminal blocks	:	2.5mm ² (5 pole.)
Maximum Installed Voltage	:	400 Volt

Spelsbera model	SEMKO Approval	Ref. No.	Dimensions (mm)			Cable entries
			L	W	D	
Sd7	✗	332-407	75	75	37	7
Sd7	✗	332-907	75	75	37	7
i12	✓	332-412	85	85	37	12
i12	✓	332-912	85	85	37	12

Ref. No.	Description
332-407	Sd7 with terminal block
332-907	Sd7 no terminal block
332-412	i12 with terminal block
332-912	i12 no terminal block