


DC Power Connectors

Order code	Manufacturer code	Description
23-1210	PX0646	3 POLE SOCKET & STRAIN RELIEF

DC Power Connectors	Page 1 of 2
The enclosed information is believed to be correct, Information may change 'without notice' due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E.	Revision A 04/07/2003

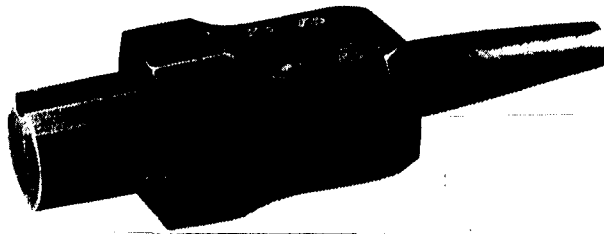

- 2 pole + Earth.
- Connection:** Solder tags.

Max. Rating: 3A. 250V a.c.
Contact Resistance: <10m
Insulation Resistance: >10⁵ M
A.C. Breakdown: Pole-Pole 4.5kV. Pole-Panel 8.5kV.
Operating Temperature: -20°C to +60°C
Materials:-
Mouldings: 23-1210 - Nylon & glass filled nylon.
Contacts: 23-1210 - Sockets brass, silver plated.

