


PX0800 Datasheet

Product Name // Mini Series Flex Cable Connector Body
5mm-7mm Cable (White Gland)

 [View Product Page](#)



61.5 Max. Depending on Cable Dia. / Pin or Socket Carrier.

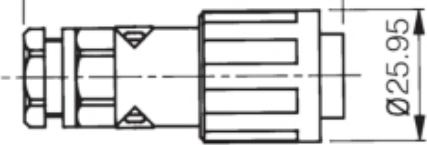

// Product Description:

- Mini Series of modular connectors
 - Water and dustproof to IP68 when mated with compatible connector
 - Choose type of connector body:
 - Part codes prefixed PX0800 - Flex Cable Connectors (mate with PX0801 Inline Cable Connectors, PX08 Mini Series Panel Mount Connectors), optionally choose cable acceptance
 - Part codes prefixed PX0801 - Inline Cable Connectors (mate with PX0800 Flex Cable Connectors), optionally choose cable acceptance
 - Part codes prefixed PX0802, PX0803, PX0804, PX0805 - Panel Mount Connectors (mate with PX08 Mini Series Flex Cable Connectors)
 - Choose type of contacts from Screw Terminal, Solder/Crimp Contacts, BNC
 - Choose number of connector Contacts and select appropriate connector insert/contact carrier:
- Screw Terminal inserts available separately in 2, 3, 4, 6 Contact, Pin or Socket
 - Solder, Crimp Contact carriers available separately in 3, 8 Contact; select appropriate Contact Pins or Sockets and Polarising/Blanking Pins, Contact Insertion Tool, Crimping Tool as required (all available separately)
 - BNC Plug or Socket insert available separately in 50 Ohm, 75 Ohm versions for all connector body styles except PX0803
 - PX0800, PX0801 Flex and Inline Cable Connector bodies have a choice of cable acceptance 3.5mm-9mm diameter depending on part code (see data for details)
 - Pack of Cable Glands for differing cable sizes also available separately (PX0812)
 - Sealing Caps (available separately) can be used to maintain IP rating of unmated connectors:
 - PX0811 fits PX0800 Flex Cable Connector
 - PX0810 fits all other connectors in the PX08 Mini Series

// General Information:

Product Display Title:	Mini Series of modular connectors
Product Family:	Circular Power Connectors
Product Series:	Mini Buccaneer
Approvals:	UL
Body Material:	Polyamide (PA)
Body Material Type:	Plastic Body
Coupling Type:	Screw
Diameter Over Coupling Ring Mm:	26mm
Flamability Rating:	UL94V-0
Function:	Flex Cable Connector Body
Ip Rating:	IP68
Max Cable Entry Size:	7mm
Min Cable Entry Size:	5mm
Max Operating Temperature:	+70°C
Min Operating Temperature:	-20°C

// Product PDF Links

-  Mini Series power connectors...
-  Mini Series connectors wiring...

// Product 3D CAD Model Links

-  PX08003D CAD Model



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)