


PX0414/1M50 Datasheet

Product Name // **Front Panel Mount SMB Jack Connector**
1.5M cable PX0414 Series

 [View Product Page](#)

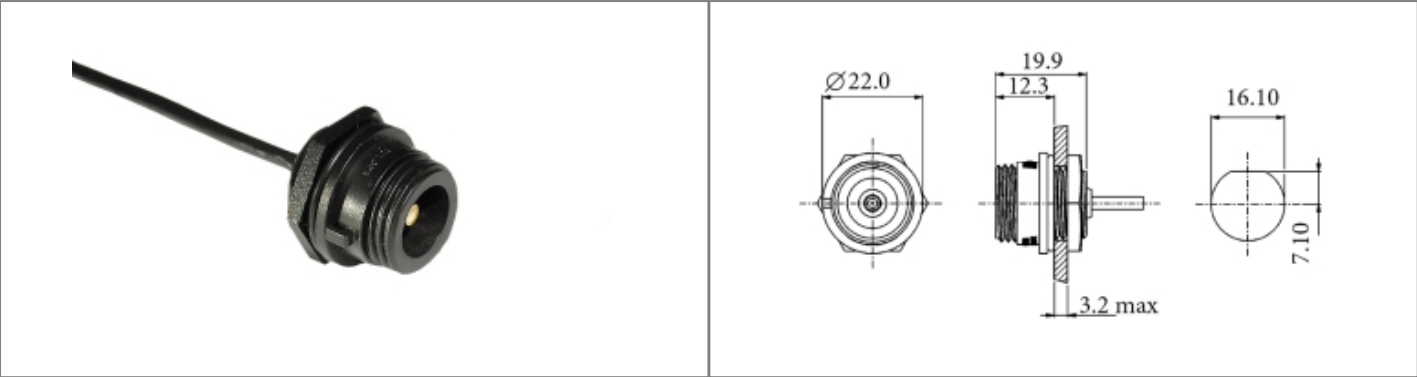

// **Product Description:**

- Front Panel Mount SMB Connector
 - Water and dustproof to IP68 when mated with compatible connector
 - Frequency range 0-4GHz
- Supplied with 50 Ohm impedance SMB plug terminated with RG-174 cable in a choice of cable lengths depending on part code (U.FL cable version also available on request)
 - PX0480 Sealing Cap available separately to maintain IP rating of unmated connectors
 - Mate with Flex Connectors PX0415, PX0416

// **General Information:**

Product Display Title:	Front Panel Mount SMB Connector
Product Family:	Circular Data Connectors
Product Series:	400 Series - SMB Buccaneer
Approvals:	CSA, UL, VDE
Body Material:	Polyamide (PA)
Body Material Type:	Plastic Body
Cable Length:	1.5m
Contact Type:	Socket Contact
Coupling Type:	Screw
Diameter Over Coupling Ring Mm:	19.1mm
Flamability Rating:	UL94V-0
Function:	Front Panel Mount Connector
Ip Rating:	IP68, IP69K
Max Operating Temperature:	+80°C
Min Operating Temperature:	-40°C
Number Of Contacts:	1 Contact

// **Product PDF Links**



// **Product 3D CAD Model Links**



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)