
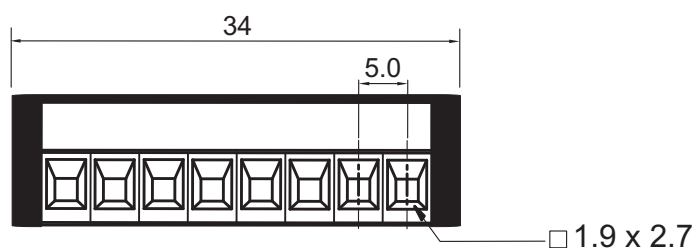
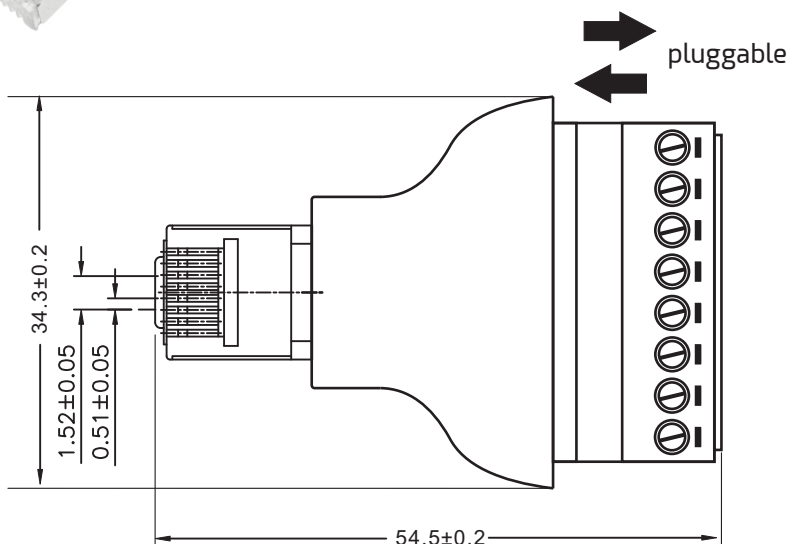


## RJ45 Terminal Adaptor

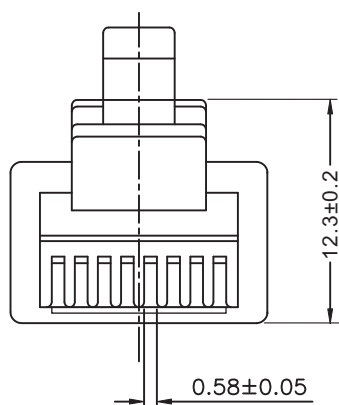

## Technical Data:

### Electrical:

Voltage rating: 12VDC

Current rating: 1.5A

Contact resistance: 50mΩ max.

Insulation resistance: 1000MΩ / 500VDC

Wire range: 26-12AWG

### Mechanical:

Torque: 0.5Nm (4.4lb/in)

Operating temperature: -40°C to 105°C

Strip length: 7mm

### Connect information

RJ plug	Terminal
8	8
7	7
6	6
5	1
4	2
3	5
2	4
1	3

