


Data Sheet

RJ12 Western plug for flat cable, 6-pin Plug, straight Transparent, 5pcs

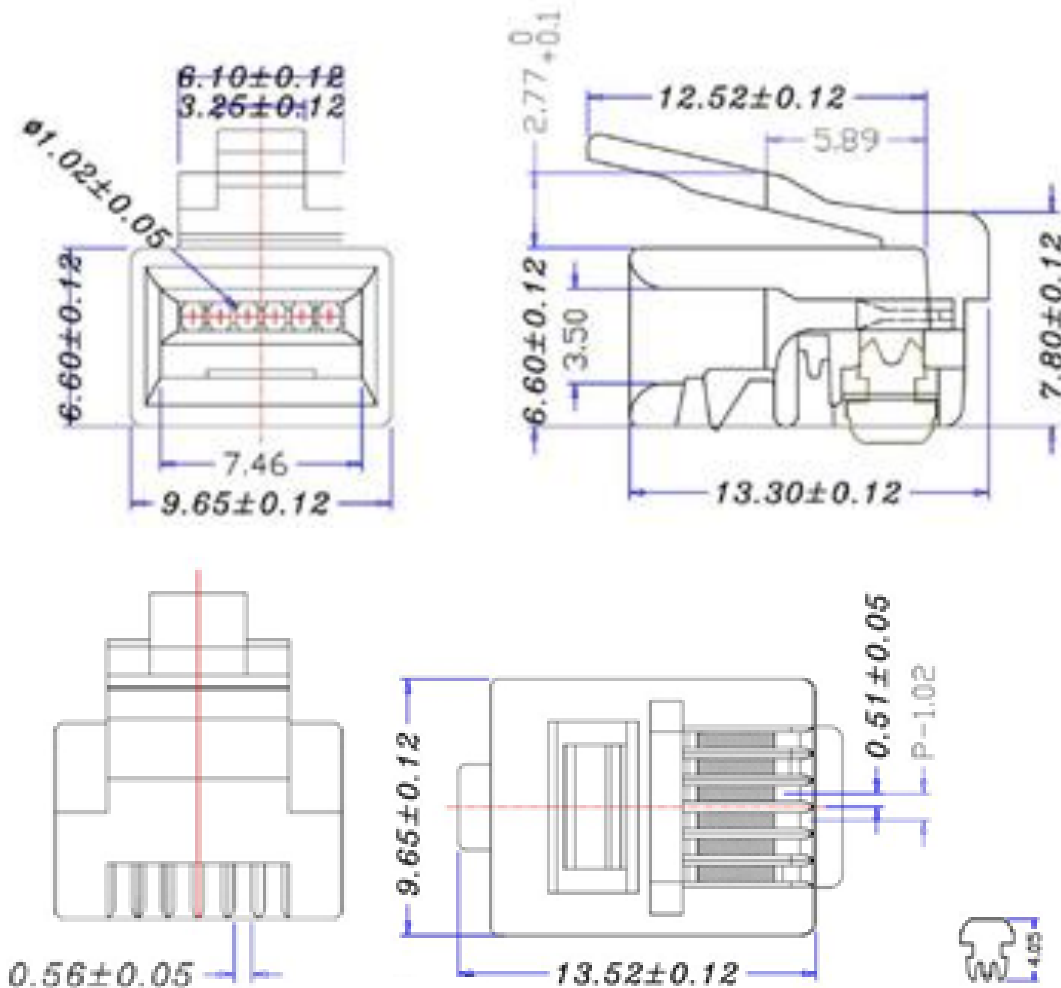

FEATURES:

1 Electrical Test:

- A. 250V AC max at 2 amps.
- B. Dielectric with standing 500volts AC.
- C. Insulation Resistance: 500 megaohms.
- D. Termination Resistance: 35megaohms.

2 Mechanical:

- A. Cable-to-Plug tensile strength-20LBs(89N)
- B. Durability: 500 mating cycles.
- C. gold plating($\square 01, \square 03, \square 06, \square 15, \square 30, \square 50$)U*

Data Sheet

Technical data

Content: 5 pcs

Colour: Transparent

Type: RJ12 plug

No. of pins: 6P6C

Connector type: Straight plug

Connection: Crimp

Operation temperature: -20°C ~ +70°C

Storage temperature: -40°C ~ +80°C