

DATASHEET


USB 2.0 Panel Jack, Ø22mm

Front: Female Type A

Back: Female Type B

Version12/14

Item no.: 1229311- Silver
1229318- Black

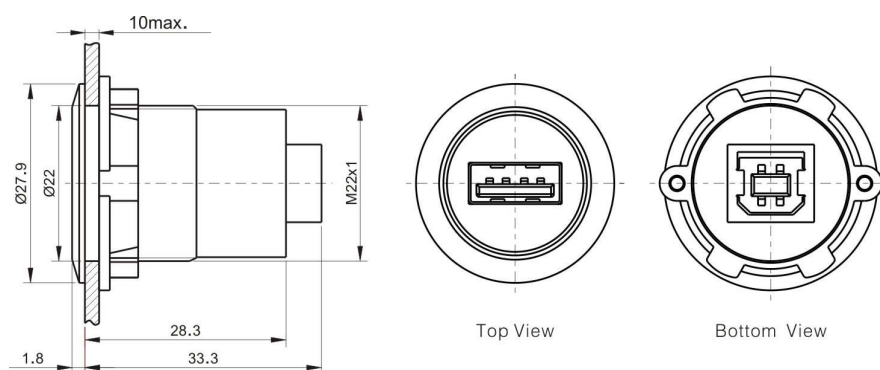

Specification	Front: Female Type A Back: Female Type B
Operating Temperature.....	-25°C ~ +55°C (NO-Freezing)
Operating Humidity.....	45~85%RH(NO Condensation)
Panel Thickness.....	1~10 mm
Body Material.....	Aluminium anodized (Silver color)
Transmission Rate	≥30MB/s