
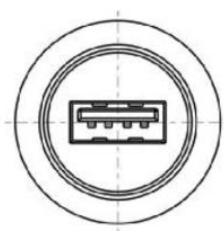


**Φ22 mm, USB2.0 Female A – Male A with 150cm cable,  
silver surface, Ring illuminated**

**BN no. 1457893 (Silver surface)**

**1457894 (Black surface)**

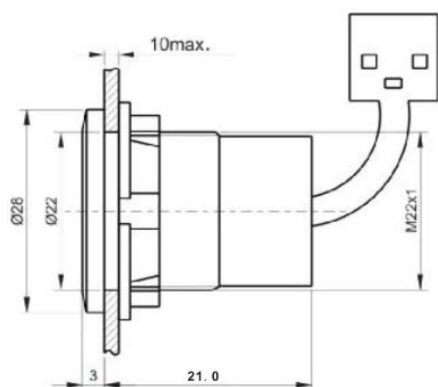

10MAX: means the panel thickness, the max thickness for the panel no more than 10mm.

Specification .....	USB2.0 Female A – Male A with 150cm cable,
Mounting diameter .....	22 mm
LED colour .....	White circle illuminated
Body material .....	PC
Cap colour .....	silver cap or black cap
Transmission Speed.....	≥30MB/s
Operating and storage temperature .....	-20 to +55 °C
Operating and storage humidity .....	10 to 85 % RH
Panel thickness .....	1 ~ 10 mm

This data sheet is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau ([www.conrad.com](http://www.conrad.com)). All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This data represent the technical status at the time of printing. Changes in technology and equipment reserved.

© Copyright 2017 by Conrad Electronic SE.