

## Datasheet

Item no. 1527942/ 1527943


V1\_0617\_01\_en

Front: Ø25 mm, 2 x USB3.0 FEMALE A

Back: 2 x MALE A with 150cm cable

BN no.: 1527942 (silver surface)

1527943 (black surface)

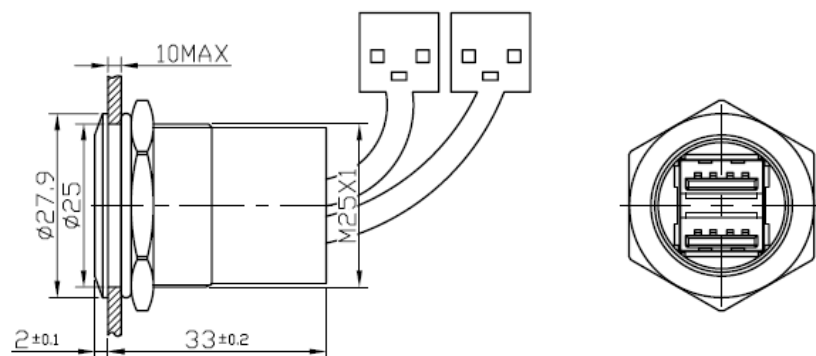

10MAX: means the panel thickness, the max thickness for the panel no more than 10mm.

Specification .....	Front: 2 x USB3.0 FEMALE Type A
	Back: MALE Type A with 150cm cable
Mounting diameter .....	25 mm
Body material .....	aluminium anodized(silver colour)
Operating and storage temperature.....	-20 to +55 °C
Operating and storage humidity.....	45 - 85 % RH
Panel thickness .....	1 ~ 10 mm
Transmission speed .....	≥100MB/s

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.