


DATASHEET

Front: Ø25 mm, 2 x USB3.0 FEMALE A
Back: 2 x MALE A with 150cm cable
BN no.: 1527942 (silver surface)
1527943 (black surface)

Version 12/16

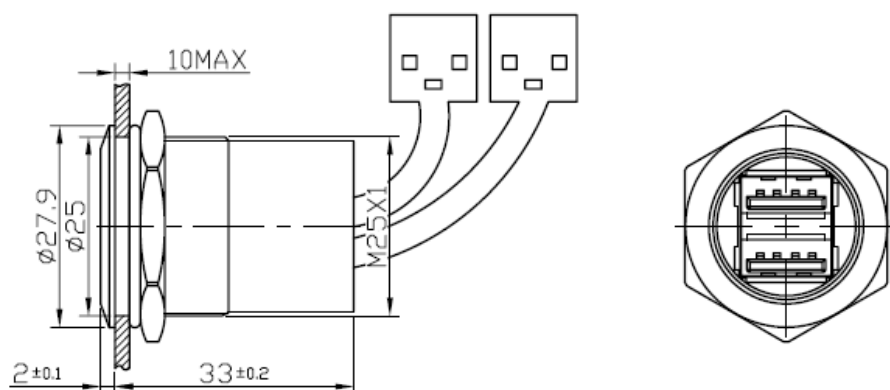

10MAX: means the panel thickness, the max thickness for the panel no more than 10mm.

Specification	Front: 2 x USB3.0 FEMALE Type A Back: MALE Type A with 150cm cable
Mounting diameter	25 mm
Body material	aluminium anodized(silver colour)
Operating and storage temperature	-20 to +55 °C
Operating and storage humidity	45 - 85 % RH
Panel thickness	1 ~ 10 mm
Transmission speed	≥100MB/s