


Data Sheet

Display Port 1.2 Front: Female Back: Female

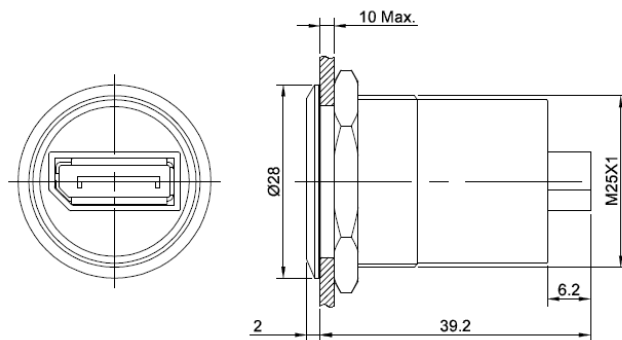

Specification

Specification	DP Female – DP Female
Mounting diameter	25 mm
Body material	Aluminium (Silver / Black)
Operating and storage temperature	-20 to +55 °C
Operating and storage humidity	10 to 85 % RH
Panel thickness	1 ~ 10 mm
Max. voltage and current	5V 0.5A
Maximum Data Rate	17.28 Gbit/s