


Data Sheet

Micro USB socket type B



Drawing:

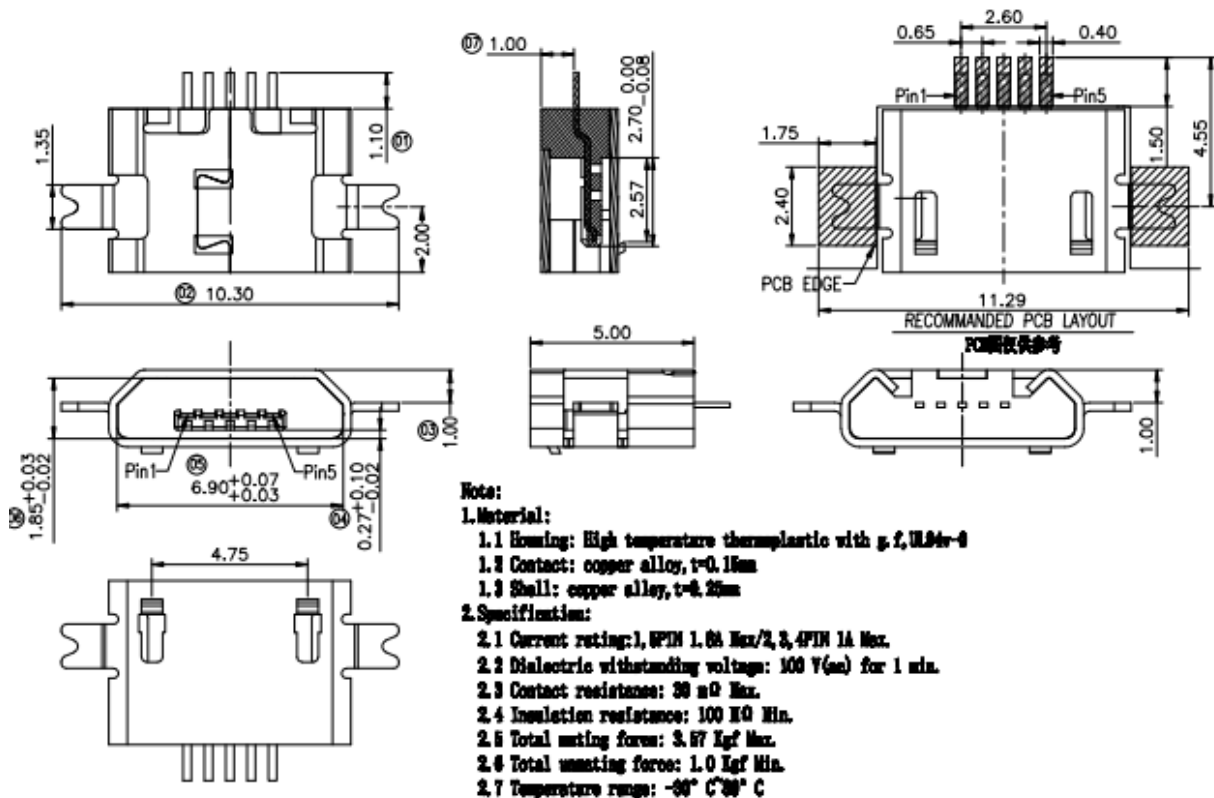

Technical data

Rate current: 1 A

Dielectric strength: 100 V for 1 min

Contact impedance: 30 mΩ max.

Insulation impedance: 100 MΩ min.

Plug life: 10000 cycles

Operation temperature: -30 °C ~ +80 °C